



iPixel LED Light Co., Ltd

Addressable LED String Light



Product Description

RGB LED chip with Micro IC built in;
DC5V, 100leds per string, 5m per string;
Cable length between each pixel 5cm;
3Pin JST SM male and female connector on each end;
Resistance IP65 for outdoor.



Colour



Blue



Red



Green



Orange



White



iPixel LED Light Co., Ltd

Product Datasheet

Product	Number	P005050CA3SD4
LED	Quantity	100leds
Emitting	Color	RGB
Operating	Voltage	DC5V
Power	(W)	0.07
Pixel	(String)	100 pcs
Control	IC	SPI
Light	Spacing	50 mm
String	Length	5000 mm
Wire	Color	Sliver
IP	Level	IP 65

Application



restaurant/bedroom/bottle

aquarium decoration

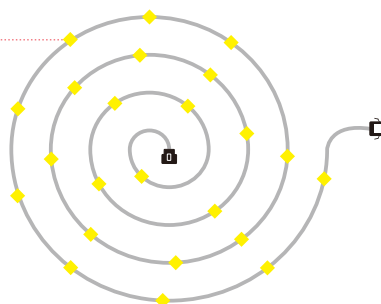


photo frame/decorative plant

marriage proposal wedding decoration,

Outline Dimension

5000 mm length
100leds/String



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SparkFun Electronics:](#)

[PRT-16792](#)