


Coaxial Cable Connector 16_MCX-50-1-11/111_N

Description

Right angle cable plug

Interface standards

IEC 60169-36_CECC 22220

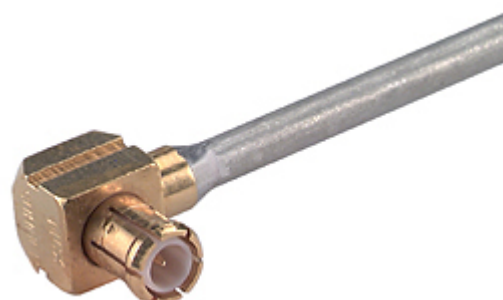

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Centre contact	soldered
Outer contact	soldered
Weight	0.000773 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00005780
Catalogue drawing	DOU-00005782
Assembly instruction	DOC-0000178655

Ordering Information

Single package	16_MCX-50-1-11/111_NE
Bulk 100 pcs package	16_MCX-50-1-11/111_NH

Additional Information

Suitable cables	EZ_47_TP_M17, SUCOFORM_47_CU
-----------------	------------------------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[16_MCX-50-1-11/111_NE](#)