


Coaxial Cable Connector 16_MMCX-50-1-7/111_O

Description

Right angle cable plug

Interface standards
SUHNER-MMCX

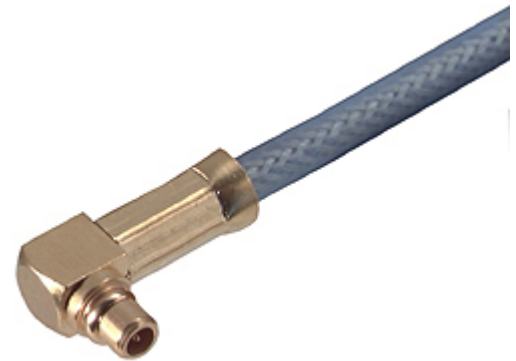

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0008 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (without Nickel underplating)
Body	Brass	Gold Plating (without Nickel underplating)
Insulator	PFA / PTFE	
Crimp ferrule	Copper	Gold Plating (without Nickel underplating)

Related Documents

Outline drawing	DOU-00007520
Catalogue drawing	DOU-00006005
Assembly instruction	DOC-0000241532

Ordering Information

Single package	16_MMCX-50-1-7/111_OE
Bulk 100 pcs package	16_MMCX-50-1-7/111_OH

Additional Information

Suitable cables	ENVIROFLEX_178_D, K_01252_D
-----------------	-----------------------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[16_MMCX-50-1-7/111_OH](#)