


Coaxial Cable Connector  
16\_SMA-50-2-110/133\_N

Description

Right angle cable plug

Interface standards  
IEC 60169-15\_MIL-STD-348A/310\_CECC 22110

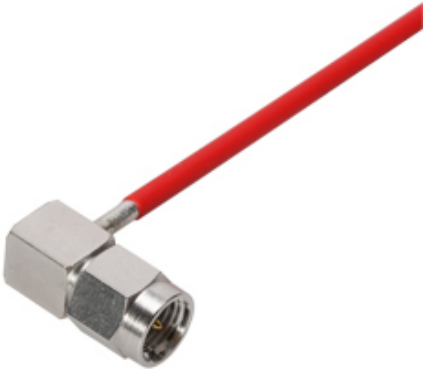

Technical Data

Electrical Data

Impedance	50 Ω		
Interface frequency max.	18 GHz		
Frequency range	DC to 1 GHz	1 to 2.5 GHz	2.5 to 5 GHz
Return loss	36 dB	32 dB	26 dB

Mechanical Data

Centre contact	soldered
Outer contact	soldered
Weight	0.0043 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	SUCOPRO Plating
Outer contact	Brass	SUCOPLATE (R) Plating
Body	Brass	Silver Plating
Insulator	PTFE (Polytetrafluoroethylene)	
Coupling nut	Brass	SUCOPLATE (R) Plating
Gasket	VMQ (Silicone rubber)	

Related Documents

Outline drawing	DOU-00170392
Catalogue drawing	DCA-00183695
Assembly instruction	DOC-0000335631

Ordering Information

Bulk 500 pcs package	16_SMA-50-2-110/133_NP
Single package	16_SMA-50-2-110/133_NE

Additional Information

Suitable cables	MULTIFLEX_86, SUCOFORM_86, EZ_86_LA_TP
-----------------	--

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[16\\_SMA-50-2-110/133\\_NP](#)