


## Coaxial Panel Connector 22\_MCX-50-0-19/111\_N

### Description

Straight bulkhead receptacle jack

Interface standards

IEC 60169-36\_CECC 22220

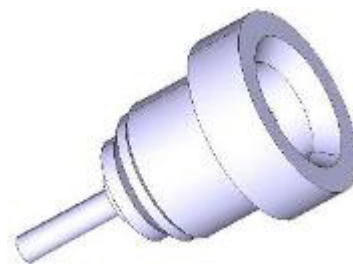

### Technical Data

#### Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

#### Mechanical Data

Number of matings	500
Weight	0.0007 kg

#### Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

#### Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	

### Related Documents

Outline drawing	DOU-00011300
Catalogue drawing	DCA-00091056
Mounting hole	DOU-00010176

### Ordering Information

Bulk 100 pcs package	22_MCX-50-0-19/111_NH
----------------------	-----------------------

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[22\\_MCX-50-0-19/111\\_NH](#)