


Coaxial Panel Connector 22_MMCX-50-0-1/111_O

Description

Straight bulkhead receptacle jack

Interface standards
SUHNER-MMCX

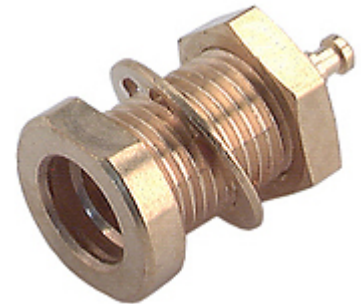

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Number of matings	500
Weight	0.0008 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (without Nickel underplating)
Body	Brass	Gold Plating (without Nickel underplating)
Insulator	PFA / PTFE	
Fastening nut	Brass	Gold Plating (without Nickel underplating)
Washer	Bronze	Gold Plating (without Nickel underplating)

Related Documents

Outline drawing	DOU-00010459
Catalogue drawing	DCA-00010461
Mounting hole	DOU-00009144

Ordering Information

Bulk 100 pcs package	22_MMCX-50-0-1/111_OH
Single package	22_MMCX-50-0-1/111_OE

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[22_MMCX-50-0-1/111_OH](#)