


Coaxial Panel Connector 23_PC35-50-0-53/199_U

Description

Straight panel receptacle jack, flange mount

Interface standards
IEC 60169-23

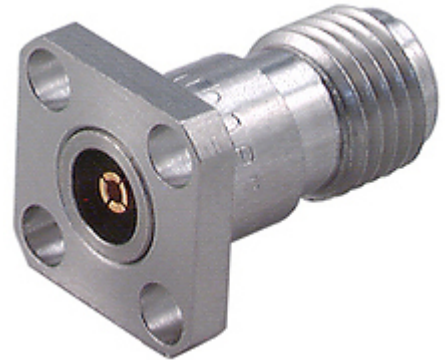

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	26.5 GHz

Mechanical Data

Number of matings	500
Weight	0.0035 kg

Environmental Data

Operating temperature	-60 °C to 100 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (without Nickel underplating)
Outer contact	Stainless Steel	
Body	Stainless Steel	
Insulator	PS (Polystyrene)	

Related Documents

Outline drawing	DOU-00011352
Catalogue drawing	DCA-00011353

Ordering Information

Single package	23_PC35-50-0-53/199_UE
----------------	------------------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[23_PC35-50-0-53/199_UE](#)