

2-way power splitter 5502.19.0004

Reactive Splitter

Description

2-Way Reactive Power Splitter for WIFI 2.4 GHz and LTE 2.3 GHz Applications



Technical Data

Electrical Data

	Signal Band 1	
Frequency	2 - 2.5 GHz	
Return Loss input port	19 dB	
Splitter Loss	3.01 dB	
Insertion Loss	3.21 dB	
Isol. between Output ports	6 dB	
Ampl. tra. betw. outp. ports	0.1 dB	
Max. Composite Power	100 W	
Peak Envelope Power	100 W	
	Input 1	
Connector Type	SMA	
Connector Gender	plug (male)	
	Output 1	Output 2
Connector Type	SMA	SMA
Connector Gender	jack (female)	jack (female)
Char. impedance	50 Ω	

Mechanical Data

Dimensions	32.3 x 23.2 x 6.35 mm (Height x Width x Length)
Weight	0.012 kg

Environmental Data

Environmental conditions	indoor/outdoor
Operation temperature	-40 °C to 85 °C
IP rating	IP20

Related Products



9075.99.0001 mounting device for power-splitters

9075.99.0002 mounting device for power-splitters

Related Documents

Outline drawing	DOU-00160031
-----------------	--------------

2-way power splitter 5502.19.0004

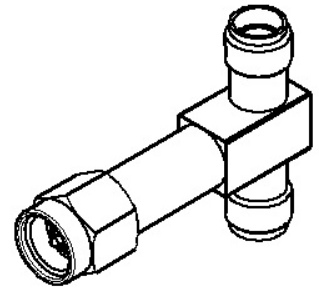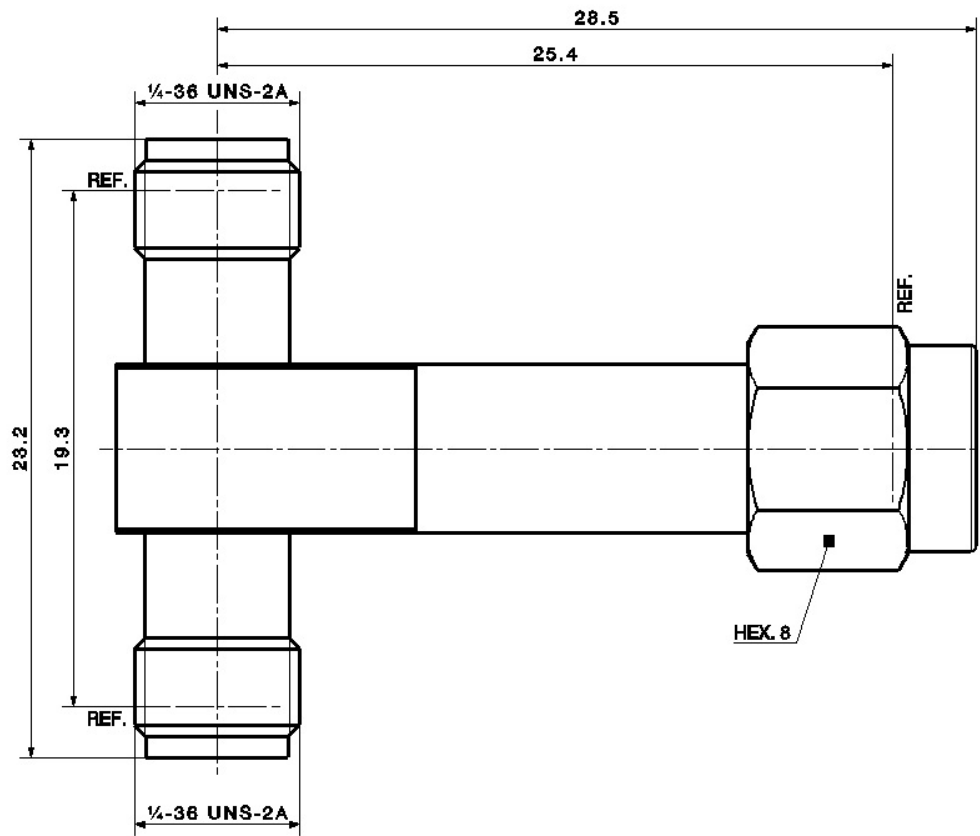

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

5502.19.0004