


Coaxial PCB Connector 81_MCX-50-0-9/111_N

Description

Straight PCB plug

Interface Standards

IEC 60169-36_CECC 22220

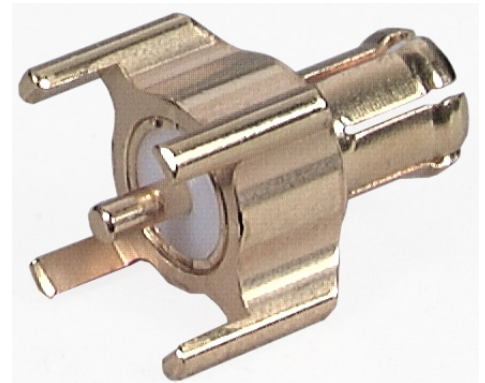

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Board mounting type	through holes
Weight	0.0007 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Brass	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00012631
Catalogue drawing	DCA-00091032

Ordering Information

Bulk 100 pcs package	81_MCX-50-0-9/111_NH
----------------------	----------------------

Remarks

PCB connector without stand-offs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[81_MCX-50-0-9/111_NH](#)