


Coaxial PCB Connector 81_SMB-50-0-41/111_N

Description

Straight PCB plug

Interface Standards

IEC 60169-10_MIL-STD-348A/311_CECC 22130

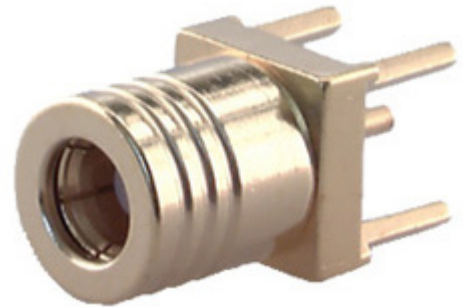

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	4 GHz

Mechanical Data

Board mounting type	through holes
Weight	0.0018 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (Nickel underplated)
Body	Brass	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00012716
Catalogue drawing	DCA-00012718
Mounting hole	DCA-00135270

Ordering Information

Bulk 100 pcs package	81_SMB-50-0-41/111_NH
Single package	81_SMB-50-0-41/111_NE

Remarks

PCB connector with stand-offs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[81_SMB-50-0-41/111_NE](#)