


Coaxial PCB Connector 82_BNC-75-0-2/122_N

Description

Straight PCB jack

Interface Standards

Interface compatible with IEC 61169-8

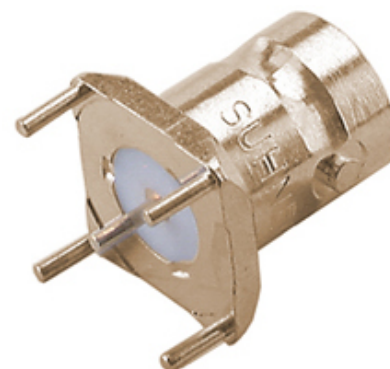

Technical Data

Electrical Data

Impedance	75 Ω
Interface frequency max.	1 GHz

Mechanical Data

Board mounting type	through holes
Weight	0.0065 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Nickel Plating
Body	Brass	Nickel Plating
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00012999
Catalogue drawing	DCA-00013001
Mounting hole	DOU-00012084

Ordering Information

Bulk 100 pcs package	82_BNC-75-0-2/122_NH
Single package	82_BNC-75-0-2/122_NE

Remarks

PCB connector with stand-offs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[82_BNC-75-0-2/122_NH](#)