


Coaxial PCB Connector 82_MCX-75-0-4/111_N

Description

Straight PCB jack

Interface Standards
SUHNER-MCX75

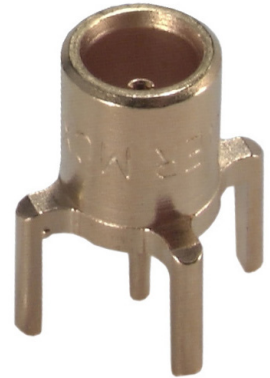

Technical Data

Electrical Data

Impedance	75 Ω
Interface frequency max.	6 GHz

Mechanical Data

Board mounting type	through holes
Weight	0.0006 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (Nickel underplated)
Body	Brass	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00013381
Catalogue drawing	DCA-00013383

Ordering Information

Bulk 100 pcs package	82_MCX-75-0-4/111_NH
Single package	82_MCX-75-0-4/111_NE

Remarks

PCB connector without stand-offs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[82_MCX-75-0-4/111_NH](#)