


Coaxial PCB Connector 82_MMBX-S50-0-3/111_N

Description

Straight PCB jack

Interface Standards
SUHNER-MMBX

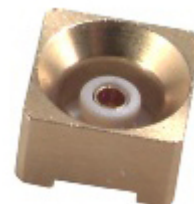

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	12.4 GHz

Mechanical Data

Board mounting type	surface mount
Weight	0.0006 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	LCP (Liquid crystal polymer)	

Related Documents

Outline drawing	DOU-00012608
Catalogue drawing	DCA-00012610
Mounting hole	DOU-00012611

Ordering Information

Tape and Reel package	82_MMBX-S50-0-3/111_NM
Bulk 100 pcs package	82_MMBX-S50-0-3/111_NH
Single package	82_MMBX-S50-0-3/111_NE

Remarks

PCB connector with stand-offs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[82_MMBX-S50-0-3/111_NH](#)