


Coaxial PCB Connector 84_BMA-50-0-1/111_N

Description

Right angle PCB plug

Interface Standards

IEC 60169-33_MIL-STD-348A/321

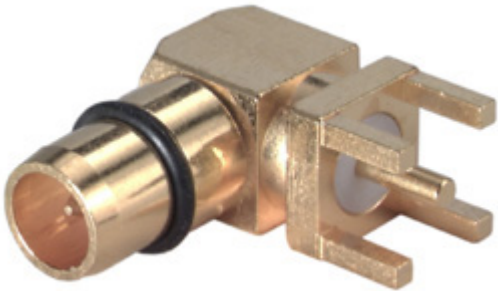

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	18 GHz

Mechanical Data

Board mounting type	through holes
Weight	0.0031 kg

Environmental Data

Operating temperature	-65 °C to 125 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium / Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	
Gasket	NR (Natural Rubber)	

Related Documents

Catalogue drawing	DCA-00012880
-------------------	--------------

Ordering Information

Single package	84_BMA-50-0-1/111_NE
----------------	----------------------

Remarks

PCB connector without stand-offs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[84_BMA-50-0-1/111_NE](#)