


Sencity Rail antenna mounting plate 9091.99.0261

Description

Mounting plate for a Sencity Rail medium or high profile antenna.
Provides optimal mechanical stability for the antenna mounting.
Allows the antenna mounting on a metal or non-metal train roof with a thickness of 0.5 to 12 mm .
Easy mounting procedure without welding.

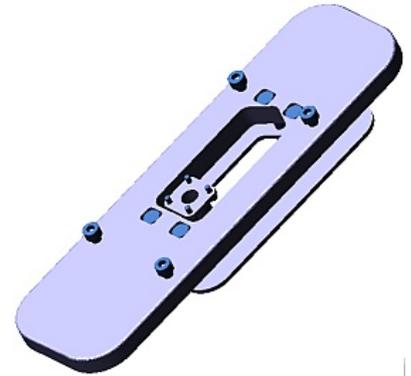

Technical Data

Mechanical Data

Weight	2.2 kg
Dimensions (mm)	20 x 108 x 360 (Height x Width x Depth)
Wind speed	survival: 500km/h
Material	Aluminium

Screws to mount the antennas are included.
Grounding kit type 9091.99.0235 included.

Environmental Data

IP rating	IP69
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Using this product slightly influences the performance of the antenna: Type 1399.99.0130: VSWR 2.3:1 in band 1350 - 1710 MHz, if mounted onto a large metal ground plane OK for smaller ground plane or if no ground plane is present.

Related Documents

Mounting instruction	DOC-0000756067
Painting instruction	DOC-0000256180
Security instruction	DOC-0000278984
Outline drawing1	DOU-00317385
3D-model (Step)	DOC-0000778659

Additional Information

This product is not compatible to all Sencity Rail antennas. Please check the datasheet of the antenna.

Sencity Rail antenna mounting plate 9091.99.0261



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[9091.99.0261](#)