

PCDS_LCMP_LCMP_O220E_...._MM

Description

Duplex patch cord, LCD push-pull to LCD push-pull, MM, duplex fig.8 2x2.0mm_XX.X_beige, OM2, A-B / B-A



Features	Features
- Push-pull mechanism for best handling and high packing density - One-piece design for easy termination - Short rigid length - Switchable duplex connectors	

Technical Data

General Data

Description	Values
General Typ	Duplex LC patch cord
Operation temperature	-25 up to 70°C
Polarity	A-B / B-A straight polarity (standard)
UL Rating	UL 94 V-0
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes

Connector left

Description	Values
Connector typ	LC duplex Push-Pull
Polish	UPC
Color Housing	Black
Color Clip	Beige
Color Boot	Black
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	M
Insertion loss 97% dB / mean dB	0.25 / 0.12
Durability	1000
Tensile load	2 x 100 N
Tensile load acc. To GR-326-COR	Fullfilled

Connector right


Description	Values
Connector typ	LC duplex Push-Pull
Polish	UPC
Color Housing	Black
Color Clip	Beige
Color Boot	Black
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	M
Insertion loss 97% dB / mean dB	0.25 / 0.12
Durability	1000
Tensile load	2 x 100 N
Tensile load acc. To GR-326-COR	Fullfilled

PCDS_LCMP_LCMP_O220E_...._MM

Cable

Description	Values
Cable typ	Duplex Cable Figure 8
Fiber count	2
Fiber	2 x 0.9 mm
Fiber type	G50/125-OM2 G.651
Outer diameter	2 mm

Technical Drawing

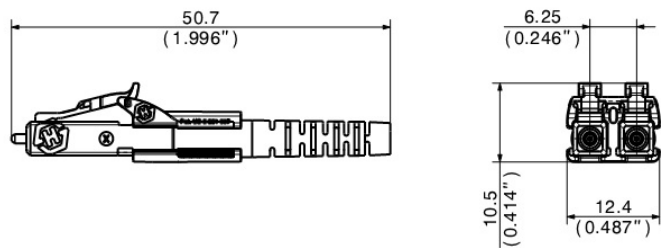

Ordering information

Meter (m)	Item number	Description
1m	85033052	PCDS_LCMP_LCMP_O220E_01.0_MMx
2m	85033053	PCDS_LCMP_LCMP_O220E_02.0_MMx
3m	85033054	PCDS_LCMP_LCMP_O220E_03.0_MMx
5m	85033055	PCDS_LCMP_LCMP_O220E_05.0_MMx

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[FLC-Z/K-B007_100-P](#)