

PCDS_LCMD_LCMD_O317E_XX.X_MM

Description

Duplex patch cord, LCD classic to LCD classic, MM, duplex fig.8 2x1.7mm_XX.X_turquoise, OM3 BendOptimized, A-B / B-A



Features	Features
- Push-pull mechanism for best handling and high packing density	
- One-piece design for easy termination	
- Short rigid length	
- Switchable duplex connectors	

Technical Data

General Data

Description	Values
General Typ	Duplex LC patch cord
Operation temperature	-25 up to 70°C
Polarity	A-B / B-A straight polarity (standard)
UL Rating	UL 94 V-0
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes

Connector left

Description	Values
Connector typ	LC duplex Classic
Polish	UPC
Color Housing	Black
Color Clip	Aqua
Color Boot	Black
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	M
Insertion loss 97% dB / mean dB	0.25 / 0.12
Return Loss	35
Durability	1000
Tensile load	2 x 100 N
Tensile load acc. To GR-326-COR	Fulfilled

Connector right

Description	Values
Connector typ	LC duplex Classic
Polish	UPC
Color Housing	Black
Color Clip	Aqua
Color Boot	Black
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	M
Insertion loss 97% dB / mean dB	0.25 / 0.12
Return Loss	35
Durability	1000


PCDS_LCMD_LCMD_O317E_XX.X_MM

Tensil load	2 x 100 N
Tensil load acc. To GR-326-COR	Fullfilled

Cable

Description	Values
Cable typ	Duplex Cable Figure 8
Fiber count	2
Fiber	2 x 0.9 mm
Fiber type	G50/125-OM3 BendOptimized
Outer diameter	1.7 mm
Outer jacket material	Jacket material according to UL 94V-0

Technical Drawing

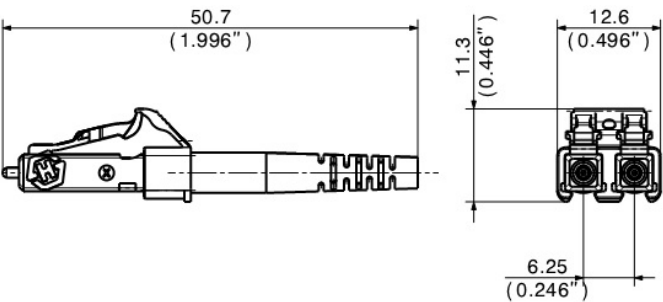

Ordering information

Meter (m)	Item number	Description
1	85022112	PCDS_LCMD_LCMD_O317E_01.0_MM
2	85022117	PCDS_LCMD_LCMD_O317E_02.0_MM
3	85022118	PCDS_LCMD_LCMD_O317E_03.0_MM
5	85022120	PCDS_LCMD_LCMD_O317E_05.0_MM
6	85022121	PCDS_LCMD_LCMD_O317E_06.0_MM
7	85022122	PCDS_LCMD_LCMD_O317E_07.0_MM
10	85022123	PCDS_LCMD_LCMD_O317E_10.0_MM
15	85022124	PCDS_LCMD_LCMD_O317E_15.0_MM
20	85022125	PCDS_LCMD_LCMD_O317E_20.0_MM
3.5	85022119	PCDS_LCMD_LCMD_O317E_03.5_MM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[PCDS_LCMD_LCMD_O317E_02.0_MM](#)