

PT01_LCAS_0000_SM09E_S0

Description

Single pigtail, LC-HQ BTW, APC, fiber 0.9mm_XX.X_yellow, SM G.652.D



Features	Features
- High mechanical stability	
- Colour coded boot for good visibility also in mated condition	

Technical Data

General Data

Description	Values
General Typ	LC pigtail
Operation temperature	-40 up to 85°C
UL Rating	UL 94 V-0
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes


Connector left

Description	Values
Connector typ	LC pigtail
Polish	APC
Color Housing	Black
Color Boot	Green
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	S
Insertion loss 97% dB / mean dB	0.25 / 0.12
Return Loss	65
Durability	1000
Performance class H+S	0

Cable

Description	Values
Cable typ	Semi-tight Tube
Fiber count	1
Fiber	1 x 0.9 mm
Fiber typ	E9/125-SM ultra G.652.D / G.657.A1

Technical Drawing

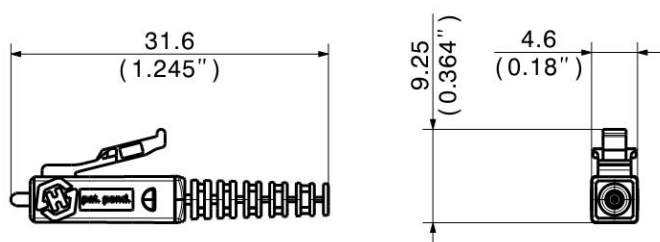

PT01_LCAS_0000_SM09E_S0

Ordering information

Meter (m)	Item number	Description
2	84130959	PT01_LCAS_0000_SM09E_02.0_S0

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HUBER+SUHNER:

[PT01_LCAS_0000_SM09E_02.0_S0](#)