

IANOS Chassis

Description

IANOS 19 inch chassis, for up to 12 IANOS modules, 1U, grey
IANOS-STD-CHASSIS-FLX-1U-2G-T4

Features

- Up to 12 x single modules or 6 x double modules
- 72 x ports (LC duplex or SC Simplex /MTP) per 1U
- Modules can be fitted from the front or the rear of chassis
- Horizontal opening front- door, separates redundant paths
- Labeling stored within front door
- Insertion and removal modules with one hand
- Same modules used for all IANOS 19 inch EDR applications



Technical data

Mechanical data


Characteristics	Values
Product family	IANOS
Suitable for	IANOS Modules
Dimension (Width x Length x Height) (mm)	482.6 x 328 x 44
Dimension (Width x Length x Height) (inch)	19 x 12.9 x 1.7
Rack height (U)	1
Weight (kg)	3.6
Weight (lbs)	7.9
Material chassis	steel
Colour chassis	telegrey 4 (RAL 7047)
Capacity of modules (pcs)	12
Compatibility	EDR
Mounting Type	Front mounting

Environmental data

Characteristics	Values
Free of halogen	Yes
RoHS compliant	Yes
REACH compliant	Yes

IANOS Chassis

Technical drawing

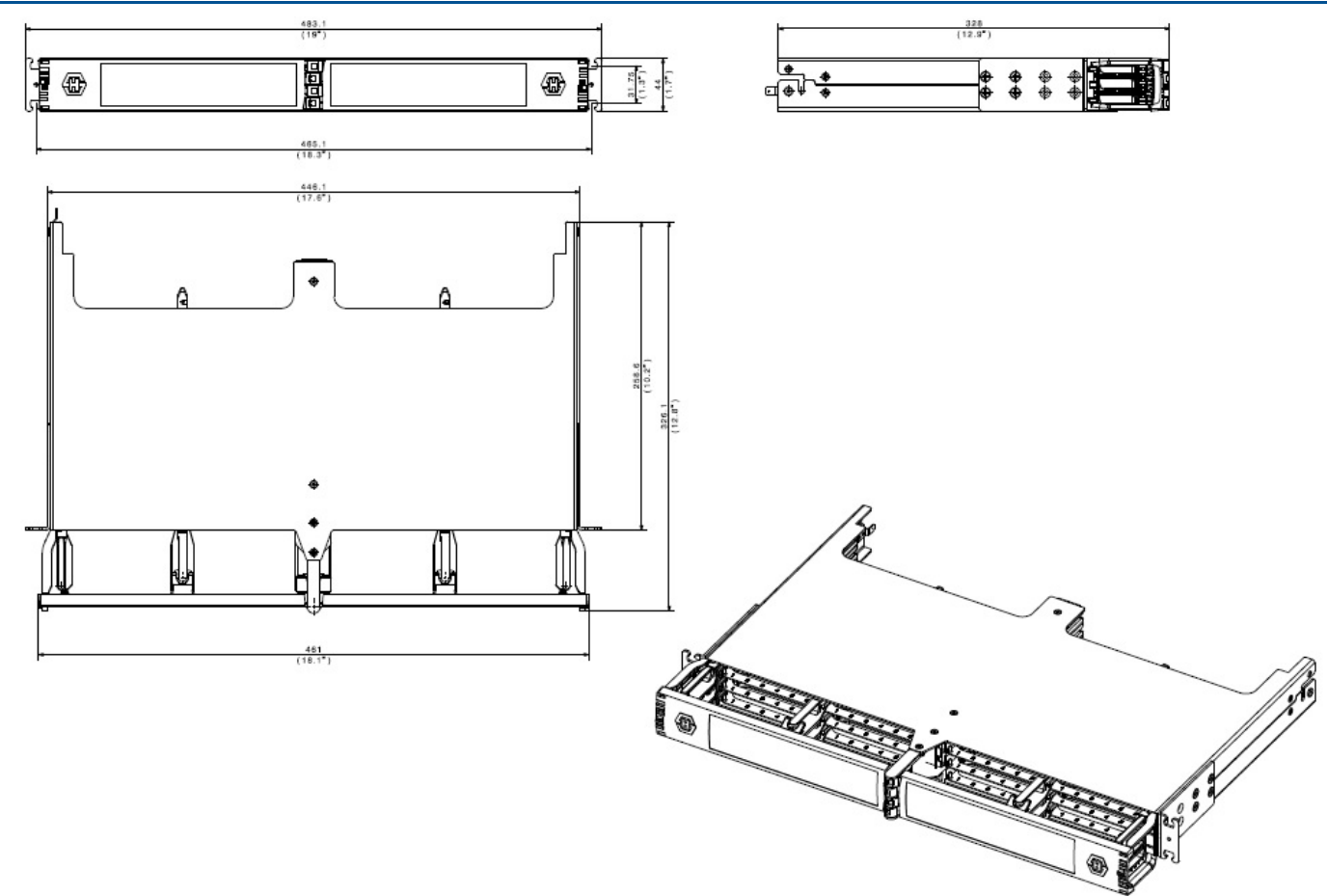

Ordering information

Description	Item number
IANOS 19 inch chassis, for up to 12 IANOS modules, 1U, grey	85102690

Related Documents

Installation manual	DOC-0000835076
---------------------	----------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[85102690](#)