

## OptiBox 4i

### Description

Optibox 4i, empty, for up to 24 splices, IP67, graphite grey  
OTB04i0-00S00P000xx0000000O-KK

#### Features

- Up to 4 adapters of SC shape
- Easy-to-use mounting splicing and patching box, consisting of base, fiber tray and cover
- Detachable fiber management tray inlay
- Radius protected fiber management with a minimum bending radius of 28 mm
- Pigtail to pigtail configuration possible
- Dedicated storage area for unused fibers
- Two different levels for managing up to 24 splices
- 1 cable entry and 2 cable exits (one at the top and one through the enclosure)
- Outside cable entries and exits are sealed with polymer cable glands
- Harsh environment protected ODC-2 (2 fibers) sockets mountable for creating "external" connections
- Optional lock available
- UV resistant enclosure
- Enclosure suitable for outdoor applications (IP67)
- Dedicated area to accommodate gas blockers if required



### Technical data

#### Mechanical data


Characteristics	Values
Application	Outdoor
Dimension (Width x Length x Height) (mm)	150 x 250 x 46
Dimension (Width x Length x Height) (inch)	5.9 x 9.8 x 1.8
Diameter cable entry (max) (mm)	16
Weight (g)	436
Weight (oz)	15.4
Material housing	ABS/PC
Colour housing	graphite grey (RAL 7024)
Minimum bending radius (mm)	28
Capacity of adaptors (pcs)	4
Capacity of splices (pcs)	24
Capacity of cable entries (pcs)	3
Mounting nature of adaptors	snapped-in

#### Environmental data

Characteristics	Values
Temperature resistance (min to max) (°C)	-46 to 81
Temperature resistance (min to max) (°F)	-50.8 to 177.8
UL Rating	UL 94 V-0
Chemical resistance	Yes
UV resistance	Yes
Resistance to impact	IK08
Ingress protection degree	IP67
Free of halogen	Yes
RoHS compliant	Yes
REACH compliant	Yes
Electrical shock resistance	Yes

OptiBox 4i

Technical drawing

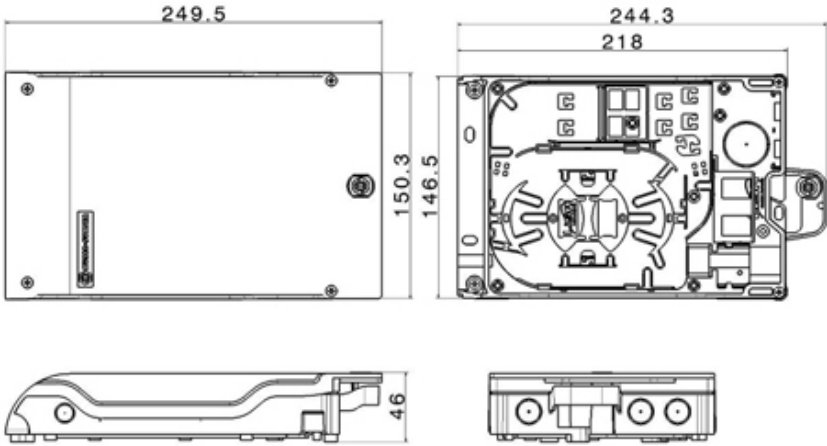

Ordering information

Description	Item number
Optibox 4i, empty, for up to 24 splices, IP67, graphite grey	84076039

Related Documents

Installation manual	DOC-0000294966
---------------------	----------------

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[84076039](#)