

## RAFIX 22 FS<sup>+</sup> - Keylock switch, square collar

**1.30.255.351/0400**

Other lock variants available on request.

Included: 2 keys.



### General information

|                     |        |
|---------------------|--------|
| Color of front ring | yellow |
| Form of collar      | square |

### Dimensions

|                      |                      |
|----------------------|----------------------|
| Dimensions of collar | 29.8 x 29.8 mm       |
| Width of collar      | 29.8 mm              |
| Overall height       | 44.1 mm              |
| Mounting depth       | PCB 9.2 mm, QC 27 mm |
| Mounting hole        | 22.3 mm              |
| Key grid             | 30 x 30 mm           |

### Mechanical design

|                             |                 |
|-----------------------------|-----------------|
| Mounting                    | ring nut        |
| Lock                        | Micromec        |
| Contact function            | latching        |
| Wafers                      | 5               |
| Illuminability              | no              |
| Lock type                   | 001             |
| Number of locking positions | 500             |
| Main key                    | on request      |
| Rotating angle              | 1 x 90°, form V |
| Key removal position        | 0               |
| Torque for nut ring         | 1.2 Nm          |

### Mechanical characteristics

 

|             |        |
|-------------|--------|
| Torque max. | 1.3 Nm |
|-------------|--------|

### Other specifications

|                                      |                                                                     |
|--------------------------------------|---------------------------------------------------------------------|
| Operating life                       | 300,000 momentary / 50,000 latching / 30,000 with key removal cycle |
| B10                                  | 400,000 momentary / 65,000 latching / 40,000 with key removal cycle |
| Degree of protection from front side | IP65 (DIN EN 60529)                                                 |
| Ambient temp. operating min.         | -25 °C                                                              |
| Ambient temp. operating max.         | +70 °C                                                              |
| Storage temperature min.             | -40 °C                                                              |
| Storage temperature max.             | +80 °C                                                              |

|                                |                                          |
|--------------------------------|------------------------------------------|
| Environmental resistance       | acc. to IEC 60068-2-14, -30, -33 and -78 |
| ESD-strength lock / contact    | 15 kV                                    |
| ESD-strength key / front panel | 15 kV                                    |
| Salt spray                     | IEC 600 68-2-11                          |
| ROHS compliant                 | yes                                      |
| REACH compliant                | yes                                      |

Panel cut-out to IEC 60947-5-1

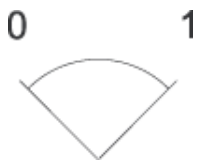

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

RAFI:

[1.30.255.351/0400](https://www.mouser.com/ProductDetail/RAFI/1.30.255.351/0400)