

Signal lamps with lamp socket - BA 15d, IP40, 30.5 mm, housing

1.63.521.099/0000

Please include the desired lens and LED / lamp in your order.



General information

Form of lens	round
Color of lens	-
Diameter of collar	36 mm

Dimensions

Mounting depth	58 mm
Mounting hole	30,5 ^{+0,5} mm

Mechanical design

Mounting	ring nut
Terminals	quick connector for 2 x 2.8 x 0.8 mm
Lamp socket	BA 15 d
Lamp	LED or filament lamp


Electrical characteristics

Voltage limit max.	250 V
Power limit max.	5 W


Other specifications

Degree of protection from front side	IP40 (DIN EN 60529)
Weight	40 g
ROHS compliant	yes
REACH compliant	yes

lens form 1

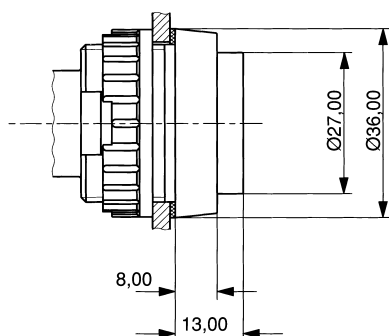

lens form 3

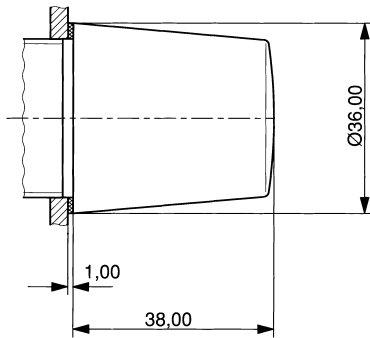

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[RAFI:](#)

[1.63.521.099/0000](#)