

RF 19 - Signal indicator, ½ x 2-module

3.14.002.908/0000

For more information, see LEDs.



General information

Color of lens	red
Recommended key grid	23/x mm

Dimensions


Length	38 mm
Width	9.5 mm
Overall height	9.15 mm


Mechanical design

Mounting	THT soldering in PCB
Illumination	fully illuminated 3 LED
LED color	red
LED type	2 mm


Other specifications

Ambient temp. operating min.	-25 °C
Ambient temp. operating max.	+70 °C
Environmental resistance	acc. to IEC 60068-2-14, -30, -33 and -78
Solderability / solder heat resistance	according to DIN EN 60068-2-20
Wave soldering	260 °C max.
Manual soldering	350 °C / 5 sec. max.
ROHS compliant	yes
REACH compliant	yes

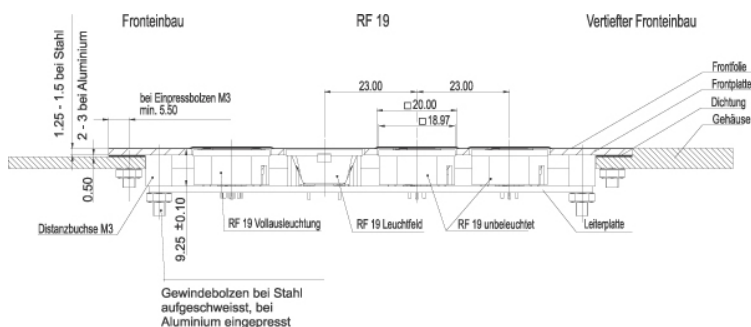

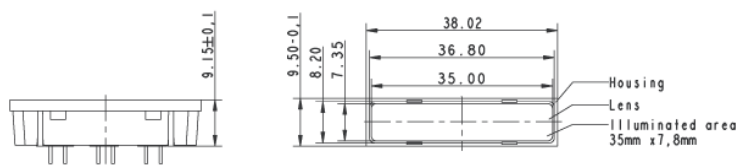

0,5 x 2-module, yellow

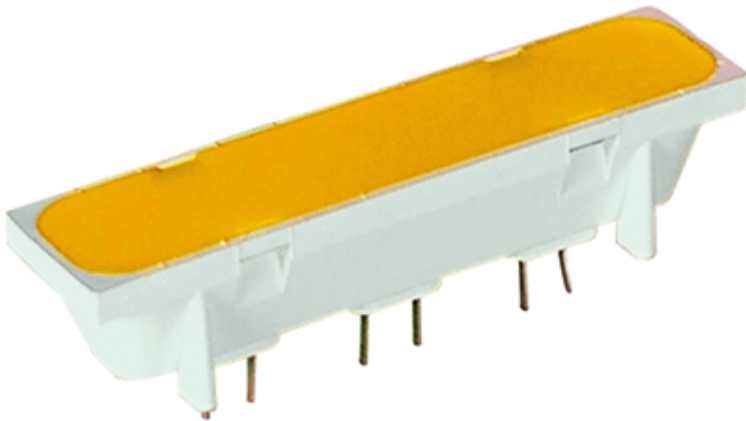

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[RAFI:](#)

[3.14.002.908/0000](#)