

RF 15 - Signal indicator, fully illuminated, 1 LED

3.14.200.052/0000

For more information, see LEDs.



General information

Colour of lens	green
Recommended key grid	19.05 mm

Dimensions


Length	15 mm
Width	15 mm
Overall height	9.15 mm

Mechanical design

Mounting	THT soldering in PCB
Illumination	fully illuminated 1 LED
LED colour	green
LED type	2 mm

Other specifications

Ambient temp. operating min.	-25 °C
Ambient temp. operating max.	+70 °C
Environmental resistance	acc. to IEC 60068-2-14, -30, -33 and -78
Solderability / solder heat resistance	according to E DIN IEC 600 28-2-20
Wave soldering	260 °C max.
Manual soldering	350 °C / 5 sec. max.

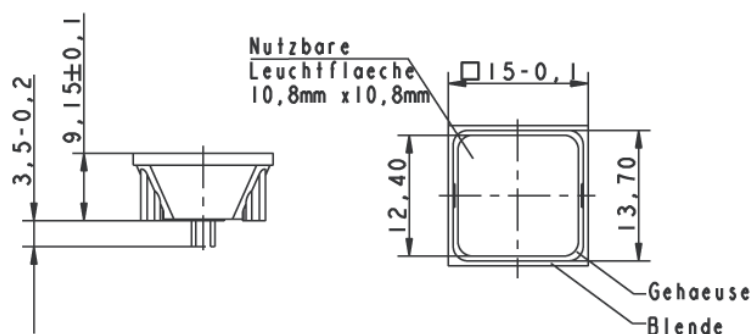

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

RAFI:

[3.14.200.052/0000](#)