

RAFIX 22 FS - Keylock switch, square collar

1.30.255.451/0700

Other lock variants available on request.



Included: 2 keys.

Approvals

TÜV

CURUS

CCC

true

General information

Colour of front ring slate-grey

Form of collar square

Dimensions

Dimensions of collar 29.8 x 29.8 mm

Width of collar 29.8 mm

Overall height 44.1 mm

Mounting depth 9.2 mm

Mounting hole 22.3 mm

Key grid 30 x 30 mm

Mechanical design

Mounting ring nut

Contact function latching

Lock Micromec

Wafers 5

Illuminability no

Lock type 001

Number of locking positions 500

Main key on request

Rotating angle 2 x 90°

Key removal position 0

Mechanical characteristics

Torque max. 1.3 Nm

Other specifications

Operating life (operations) 300.000 tastend / 50.000 rastend / 30.000 mit Schlüsselabzug cycle

Degree of protection from front side IP65

Ambient temp. operating min. -25 °C

Ambient temp. operating max. +70 °C

Storage temperature min. -40 °C




Storage temperature max. +80 °C

Environmental resistance acc. to IEC 60068-2-14, -30, -33 and -78

ESD-strength lock / contact 15 kV

ESD-strength key/ front panel 15 kV

Salt spray IEC 600 68-2-11

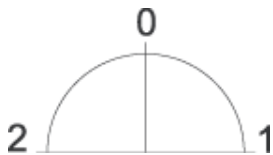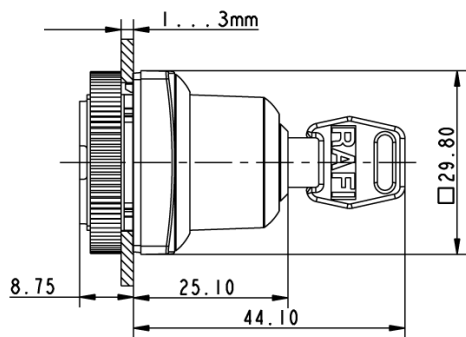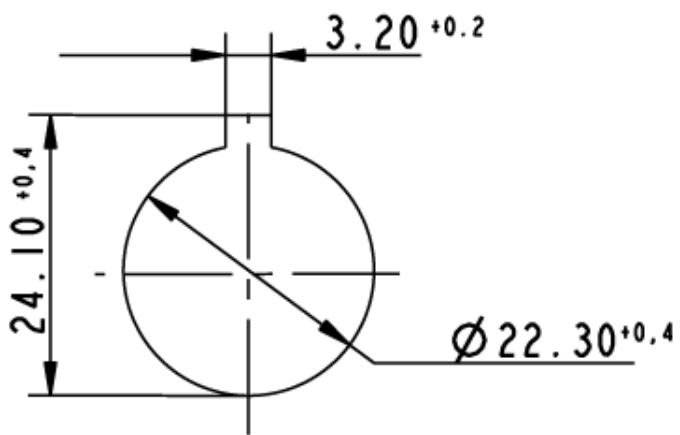

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

RAFI:

[1.30.255.451/0700](https://www.mouser.com/ProductDetail/RAFI/1.30.255.451/0700)