


Lowest Profile Push-Push MicroSD Socket

Key features

- > Super low profile at 1.28mm
- > Real estate of less than 184mm²
- > Push-push ejector mechanism

MEM2080 is the slimmest MicroSD memory card connector on the market, making it ideal for applications where space is at a premium. Additional features include a card detection switch in a normally open configuration, an operating temperature of between -25°C and +85°C and testing to 5,000 mating cycles.

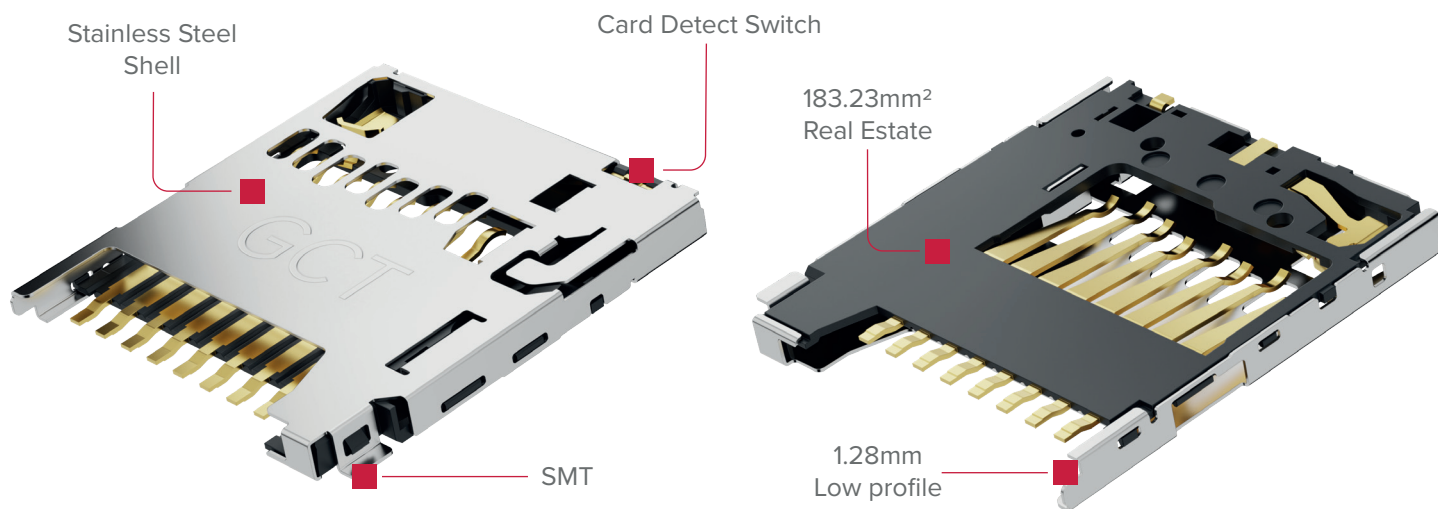

Product Specifications

Low Profile	Card Insertion	Mating Cycles	Operating Temp	Real Estate	Mount Type	Shell & Latch
1.28mm	Push-Push	5,000	-25°C and +85°C	183.23mm ²	SMT	Stainless Steel

Applications

gct.co/connector/mem2080



Portable Audio Hardware



Digital Cameras



Aerial Drones



Security Camera

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[GCT:](#)

[MEM2080-00-128-00-A](#)