

Lens Evetar M118B0418 F1.8 f4mm 1/1.8"

Order Numbers


- 2000036384 (without IR cut filter)
- 2000036385 (with IR cut filter)



Key Features

- S-mount lens with optimum price/performance ratio
- 1/1.8" lens with fixed focal length of 4.0 mm and fixed iris of f/1.8
- Available with IR cut filter (for color cameras) or without IR cut filter (for mono cameras)

Technical Specifications	
Image Circle	1/1.8"
Focal Length	4.0 mm
Aperture	f/1.8
Iris Type	fixed
MOD	200 mm
Resolution	MP
Angle of View (D / H / V)	126° / 101° / 76°
Back Focal Length	8.0 mm
Mount	M12x0.5-6g

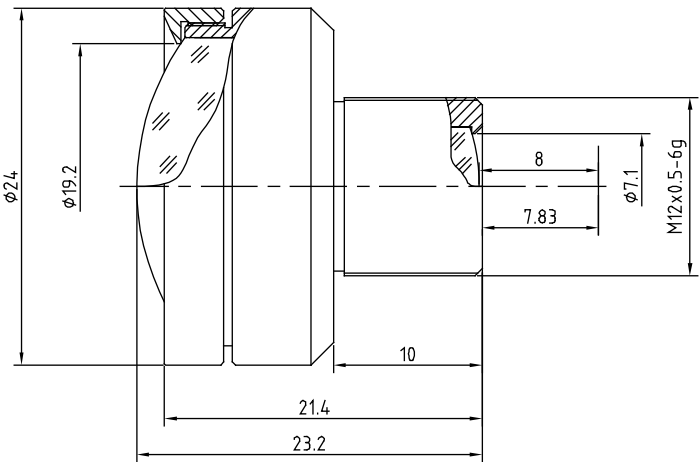

(Dimensions in mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Basler:

[2000036384](#) [2000036385](#)