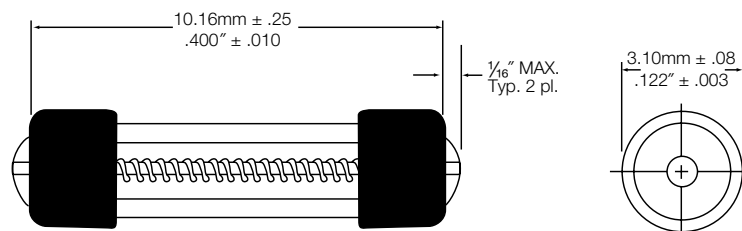
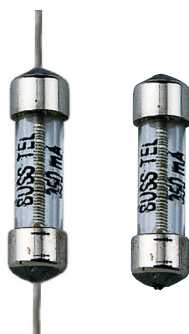


Telpower Specialty Fuse

TEL

600V DC, 350mA

**CATALOG SYMBOL:** TEL-350mA**VOLTAGE RATING:** 600V DC**INTERRUPTING RATING:** 6A DC, Battery Source**INTERRUPTION TIMES:**

4 hrs. min. @ 100% of rated current (350mA)

210 sec. max. @ 150% of rated current (525mA)

PHYSICAL SIZE: 3mm x 10mm**CONSTRUCTION:** Glass tube

Nickel-plated brass end caps

AGENCY INFORMATION:

UL Recognized, Guide No. JDYX2, File No. E19180

TELECOMMUNICATION CAPABILITIES:UL 497A: Secondary protectors for communication circuits
(Meets April 1, 1997 version of UL 497A.)

Fuses successfully passed without opening:

10 x 1000 microsecond waveform

14A peak current

50 pulses - 1 pulse every 10 seconds

50 pulses are repeated using opposite polarity

The only controlled copy of this BIF document is the electronic read-only version located on the Bussmann Network Drive. All other copies of this BIF document are by definition uncontrolled. This bulletin is intended to clearly present comprehensive product data and provide technical information that will help the end user with design applications. Bussmann reserves the right, without notice, to change design or construction of any products and to discontinue or limit distribution of any products. Bussmann also reserves the right to change or update, without notice, any technical information contained in this bulletin. Once a product has been selected, it should be tested by the user in all possible applications.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[BK-TEL-350MA](#) [BK/TEL-350MA](#)