

Description

- For 5mm x 20mm fuses
- Fuse carriers are interchangeable
- Both vertical and horizontal mounting features
- Fuse carrier and knob are spring loaded bayonet type with screwdriver slot
- Solderability in accordance with IEC 68-2-20
- Shock safety of PC2
- High temperature thermoplastic meets:
 - UL 94-VO
 - Glow wire test: 960°C per IEC 695-2-1

HTC series printed circuit board fuseholders accept 5 x 20mm fuses.

Agency Information

- UL Recognized: IZLT2, E14853A
- CSA Component Certified: Class 6225-01, File 47235



Ordering

- Specify packaging and product code



Dimensions

Drawing Not to Scale

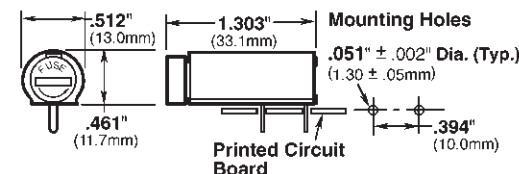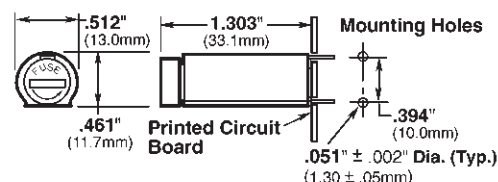

Component	Material
Clip	Tin Plating
Terminals	Copper, Tin Plated
Body	Thermoplastic

SPECIFICATIONS

Product Code	Voltage Rating AC	Current Rating Agency Approval			Ambient Temperature	Temperature Rise	Mounting
		UL	CSA	SEMKO			
HTC-45M	250V	6.3A	6.3A	6.3A	24C	41C	Vertical
HTC-50M	250V	6.3A	6.3A	6.3A	24C	41C	Horizontal

PACKAGING CODE

Packaging Code	Description
Blank	10 pieces of fuseholder packed into a carton
BK	100 pieces of fuseholders packed into a cardboard shelf package

North America

Cooper Electronic Technologies
1225 Broken Sound Parkway NW
Suite F
Boca Raton, FL 33487-3533
Tel: 1-561-998-4100
Fax: 1-561-241-6640
Toll Free: 1-888-414-2645

Cooper Bussmann
P.O. Box 14460
St. Louis, MO 63178-4460
Tel: 1-636-394-2877
Fax: 1-800-544-2570

Europe

Cooper Electronic Technologies
Cooper (UK) Limited
Burton-on-the-Wolds
Leicestershire • LE12 5TH UK
Tel: +44 (0) 1509 882 737
Fax: +44 (0) 1509 882 786

Cooper Electronic Technologies
Avda. Santa Eulalia, 290
08223
Terrassa, (Barcelona), Spain
Tel: +34 937 362 812
+34 937 362 813
Fax: +34 937 362 719

Asia Pacific

Cooper Electronic Technologies
1 Jalan Kilang Timor
#06-01 Pacific Tech Centre
Singapore 159303
Tel: +65 278 6151
Fax: +65 270 4160

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Cooper Bussmann:

[BK1-HTC-211M](#) [BK1-HTC-220M](#) [BK1-HTC-78M](#)

Eaton:

[BK1/HTC-150M](#) [BK1/HTC-220M](#) [BK1/HTC-78M](#) [BK1/HTC-211M](#)