

Ferrule

FWL/FWS 1250V/1500V 2-30A


Electrical Characteristics				Ordering Information				Dimensions	Curves
Size	Rated Current RMS-Amps	I ² t (A ² S)		Watts Loss	Part Number	Carton Qty.	Carton Weight (kg)	Figure Number	See Page or (BIF #)
		Pre-arc	Clearing at 1000 Vdc						
20 x 127mm (9/16")	†2	0.8	2.4	4.4	FWS-2A20F	10	1.00	Fig. 1	page 96 (35785109)
	†6	27	81	6.7	FWS-6A20F				
	†15	300	700	5	FWS-15A20F				
	†20	675	1550	5.9	FWL-20A20F				
	†30	1850	4300	7.5	FWL-30A20F				

- Interrupting rating 45kA RMS Symmetrical.
- Rated voltage (IEC) †1500V †1250V
- 1000 Vdc rating.
- See accessories on page 90.

1 kg = 2.2 lbs. 1 lb = 0.45 kg

Dimensions

Fig. 1: 2-30 Amp Range

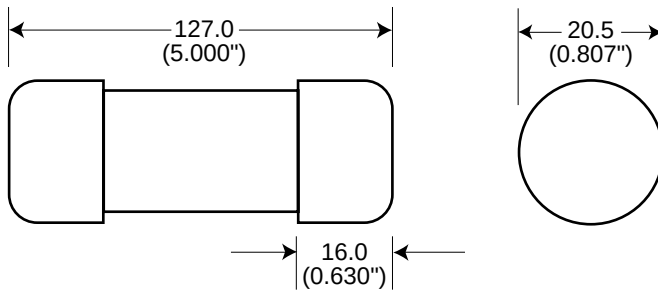

Dimension in mm.
1mm = 0.0394" 1" = 25.4mm

This bulletin is intended to clearly present comprehensive product data and provide technical information that will help the end user with design applications. Bussmann reserves the right, without notice, to change design or construction of any products and to discontinue or limit distribution of any products. Bussmann also reserves the right to change or update, without notice, any technical information contained in this bulletin. Once a product has been selected, it should be tested by the user in all possible applications.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[FWL-20A20F](#) [FWL-20A20FI](#) [FWL-25A20F](#) [FWL-25A20FI](#) [FWL-30A20F](#) [FWL-30A20FI](#) [FWS-100](#) [FWS-15A20F](#)
[FWS-15A20FI](#) [FWS-2A20F](#) [FWS-2A20FI](#) [FWS-6A20F](#) [FWS-6A20FI](#) [FWS-8A20F](#) [FWS-8A20FI](#)