


## Description

- In-Line Fuseholders for MAXI® Fuses.
- Voltage Rating: 32Vdc maximum
- Current Rating: See Table
- Firewall mounting hole permits two or more holders to be mounted together. Cover comes with a removable strap.

## Ordering

- Specify packaging and product code

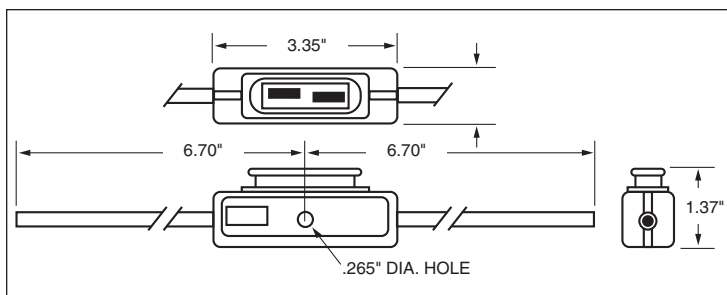

MAXI® Fuse Blade Type Holder				
Catalog Code	Description	Fuse Size	Electrical Connection	Maximum Continuous Current Rating
HHX	Black fuseholder w/cover	20-60A	#6 red lead wire;	48A*
HHX-B	Black fuseholder - Body only		5" length with blunt ends	
HHX-C	Black cover only			

\* or 80% of fuse rating, whichever is less

**A fuse must be properly and fully inserted into the holder to provide a solid connection. Poor or improper insertion of the fuse can result in failure of the fuse and holder, thus not protecting the device for which it was intended.**

PACKAGING CODE	
Packaging Code	Description
BK	100 pieces in a box

### North America

Cooper Electronic Technologies  
1225 Broken Sound Parkway NW  
Suite F  
Boca Raton, FL 33487-3533  
Tel: 1-561-998-4100  
Fax: 1-561-241-6640  
Toll Free: 1-888-414-2645

Cooper Bussmann  
P.O. Box 14460  
St. Louis, MO 63178-4460  
Tel: 1-636-394-2877  
Fax: 1-800-544-2570

### Europe

Cooper Electronic Technologies  
Cooper (UK) Limited  
Burton-on-the-Wolds  
Leicestershire • LE12 5TH UK  
Tel: +44 (0) 1509 882 737  
Fax: +44 (0) 1509 882 786

Cooper Electronic Technologies  
Avda. Santa Eulalia, 290  
08223  
Terrassa, (Barcelona), Spain  
Tel: +34 937 362 812  
+34 937 362 813  
Fax: +34 937 362 719

### Asia Pacific

Cooper Electronic Technologies  
1 Jalan Kilang Timor  
#06-01 Pacific Tech Centre  
Singapore 159303  
Tel: +65 278 6151  
Fax: +65 270 4160

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[BK/HHX](#) [BK/HHX-B](#) [HHX-20T](#) [BK-HHX](#)