

BQQ41-WH

Specifications

Description:

Quick-connect terminal block.

Rating: 30A,
600V

Center Spacing:

0.437" (11.10mm)

Number of Poles: 1

Circuits Per Foot: 24

Wire Range: For use with quick-connect terminals only.

Quick Connects: 0.250" x 0.031"

Mounting Options: Base Mount, Stackable; End Piece (Part No. BQE) is required for mounting. Mounting screws recommended every 8 circuits.

Operating Temperature: 105°C

Agency Information: UL File E62622,
CSA File 15364


Catalog Numbers

Catalog

Number	Color
BQQ41-WH	White



Dimensions - in (mm)

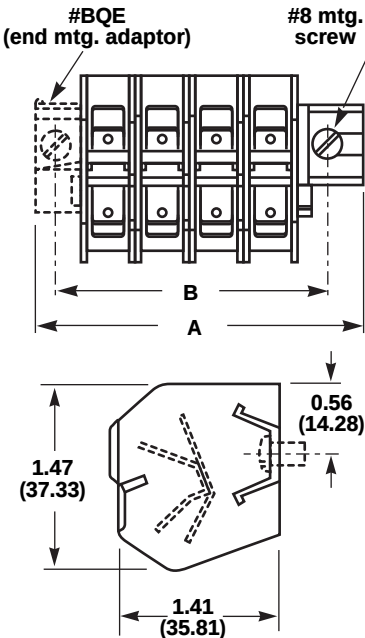

Connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cooper Bussmann:](#)

[BQQ41-WH](#)