

EM2742 Series EuroMag Terminal Blocks

Screwless; 2.54 Centers

SPECIFICATIONS

Rating: 6A, 150V

Center Spacing: 0.10" (2.54mm)

Wire Range: #20-26 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Tin-Plated Brass


Spring Material: Stainless Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.


Recommended PCB Hole Diameters: 0.051" (1.30mm)

Construction: Mold-to-Length

Agency Information:  File E62622; CE Certified

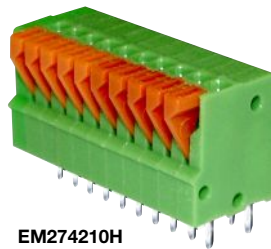


EM274210H

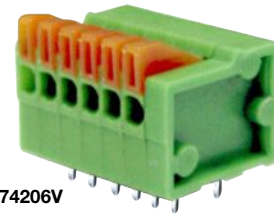


EM274206V

Dimensions - mm (in)

VERTICAL

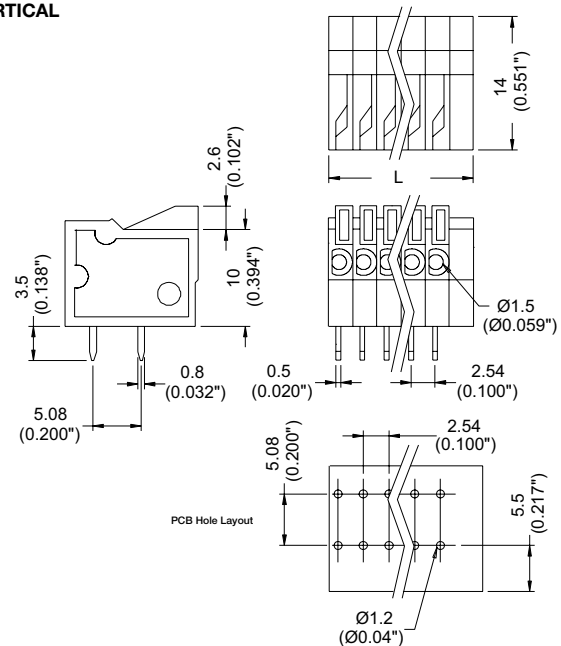

HORIZONTAL

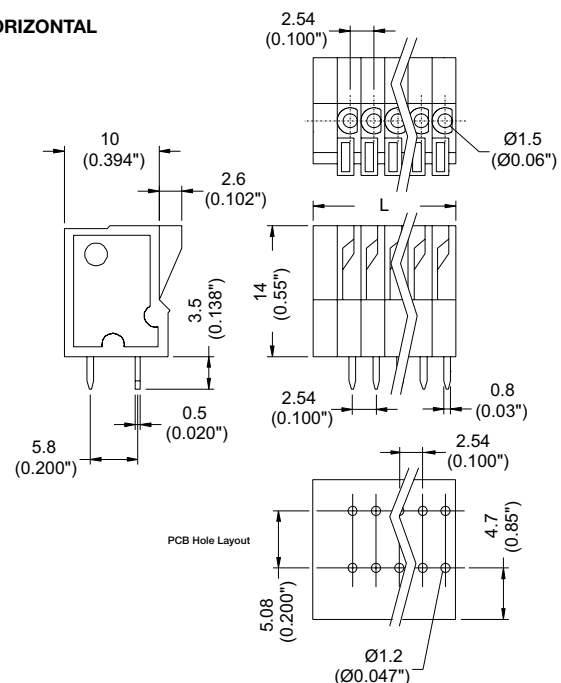

Poles	L (mm)	Poles	L (mm)
2	8.08	10	30.94
3	10.62	11	33.48
4	13.16	12	36.02
5	15.70	13	38.56
6	18.24	14	41.10
7	33.48	15	43.64
8	30.94	16	46.18
9	28.40		

To convert to inches, divide by 25.4

Part Numbering System

Series

EM2742

of Poles

02 to 16

Orientation

H - horizontal
V - vertical

Terminal Blocks:
Single Row

EuroMag Series
Screwless

Edge Connectors,
One-Sided Boards

Compliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM274215](#) [EM274213](#) [EM274214](#) [EM274206](#) [EM274202](#) [EM274205](#) [EM274207](#) [EM274210](#) [EM274208](#)
[EM274216](#) [EM274212](#) [EM274204](#) [EM274211](#) [EM274203](#) [EM274209](#)