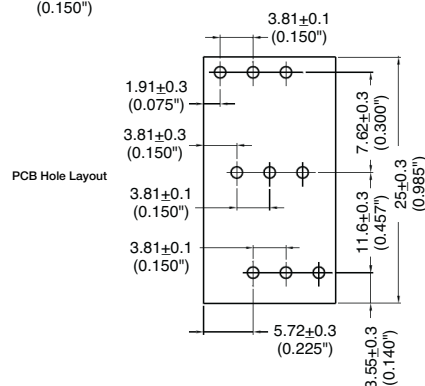
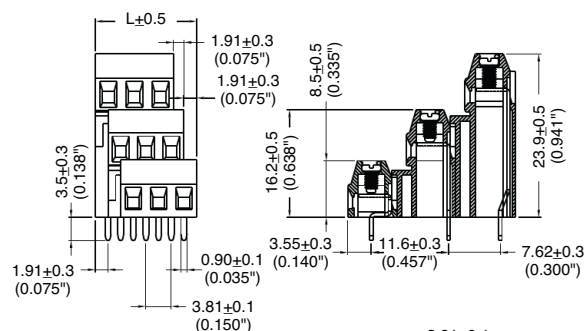
 


EM2803 Series**EuroMag Terminal Blocks**

Three Tier; 3.81 Centers; Modular

SPECIFICATIONS**Rating:** 10A, 300V**Center Spacing:** 0.150" (3.81mm)**Wire Range:** #16-26 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass Tin-Plated**Cage Material:** Brass, Nickel-Plated**Screw Size:** M2.0 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 2.0 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:** e_{us} File E62622; CE Certified

EM280302

Dimensions - mm (in)

Poles	L (mm)	Poles	L (mm)
2	11.43	8	34.29
3	15.24	9	38.10
4	19.05	10	41.90
5	22.86	11	45.70
6	26.67	12	49.50
7	30.48		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM2803

□□

02 - 12

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM280309](#) [EM280310](#) [EM280306](#) [EM280302](#) [EM280305](#) [EM280304](#) [EM280303](#) [EM280312](#) [EM280307](#)
[EM280308](#) [EM280311](#)