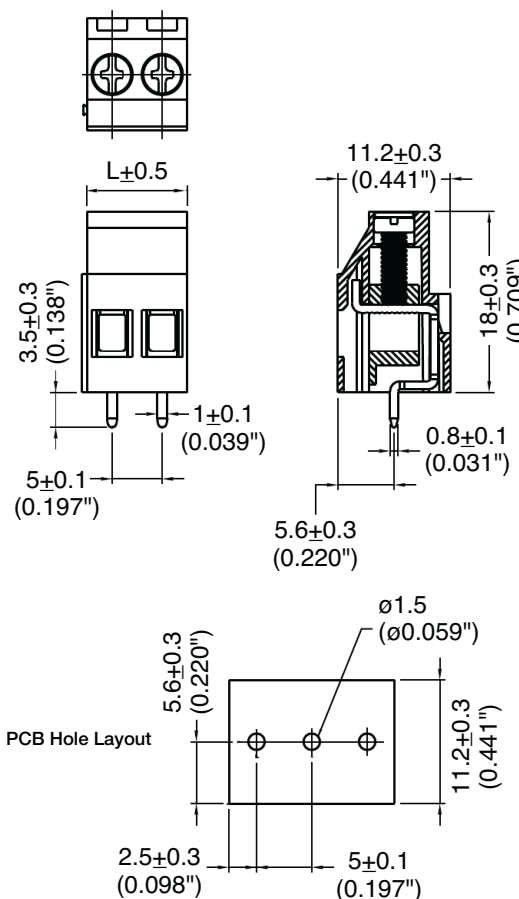


EM2905 Series**EuroMag Terminal Blocks**

High Current; 5.00 Centers; Modular

SPECIFICATIONS**Rating:** 25A, 300V**Center Spacing:** 0.197" (5.00mm)**Wire Range:** #10-24 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass Tin-Plated**Cage Material:** Brass, Nickel-Plated**Screw Size:** M2.6 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 6.0 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:**  File E62622; CE Certified

EM290508

Dimensions - mm (in)

Poles	L (mm)	Poles	L (mm)
2	10.0	14	70.0
3	15.0	15	75.0
4	20.0	16	80.0
5	25.0	17	85.0
6	30.0	18	90.0
7	35.0	19	95.0
8	40.0	20	100.0
9	45.0	21	105.0
10	50.0	22	110.0
11	55.0	23	115.0
12	60.0	24	120.0
13	65.0		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM2905

02 to 24

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM290503](#) [EM290518](#) [EM290510](#) [EM290512](#) [EM290511](#) [EM290517](#) [EM290523](#) [EM290514](#) [EM290524](#)
[EM290504](#) [EM290513](#) [EM290516](#) [EM290522](#) [EM290506](#) [EM290509](#) [EM290521](#) [EM290507](#) [EM290519](#)
[EM290508](#) [EM290520](#) [EM290502](#) [EM290505](#) [EM290515](#)