

EM3533 Series**EuroMag Terminal Blocks**

Pluggable Block (Mates with EM2221 Series);
3.50 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.138" (3.50mm)

Wire Range: #16-26 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass Tin-Plated

Cage Material: Brass, Nickel-Plated

Screw Size: M2.0 Zinc-Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

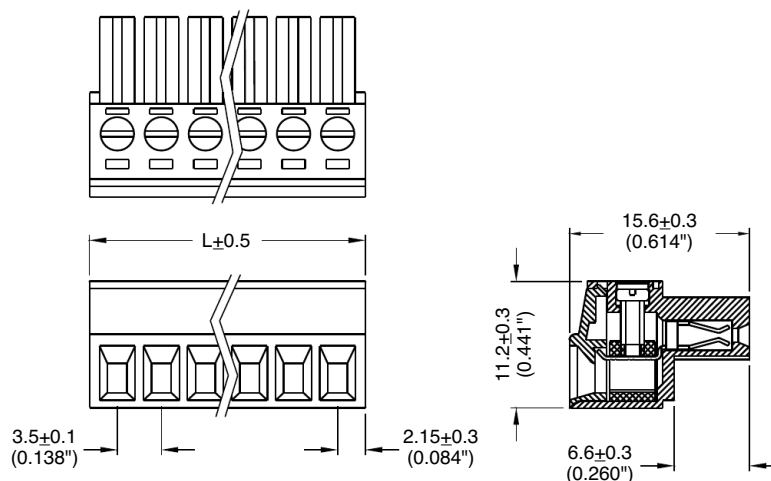
Torque Rating: 3.0 lb-in.

Construction: Mold-to-Length

Agency Information:  US File E62622; CE Certified



EM353308

Dimensions - mm (in)

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM3533

□□

02 to 14

Mating Header: EM2221 pg. 75

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM353304](#) [EM353310](#) [EM353312](#) [EM353306](#) [EM353302](#) [EM353308](#) [EM353305](#) [EM353303](#) [EM353311](#)
[EM353307](#) [EM353309](#)