

EM3675 Series

EuroMag Terminal Blocks

5.00 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.197" (5.00mm)

Wire Range: #14-26 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Tin-Plated Brass

Screw Size: M2.6 Zinc-Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Torque Rating: 4.0 lb-in.

Recommended PCB Hole Diameters: 0.055" (1.40mm)

Construction: Mold to Length

Connector Style: Spring and Screw

Agency Information:  File E62622; CE Certified




EM367512

Dimensions - (in) mm

Poles	L (mm)	Poles	L (mm)
2	10.0	15	75.0
3	15.0	16	80.0
4	20.0	17	85.0
5	25.0	18	90.0
6	30.0	19	95.0
7	35.0	20	100.0
8	40.0	21	105.0
9	45.0	22	110.0
10	50.0	23	115.0
11	55.0	24	120.0
12	60.0		
13	65.0		
14	70.0		

To convert to inches, divide by 25.4

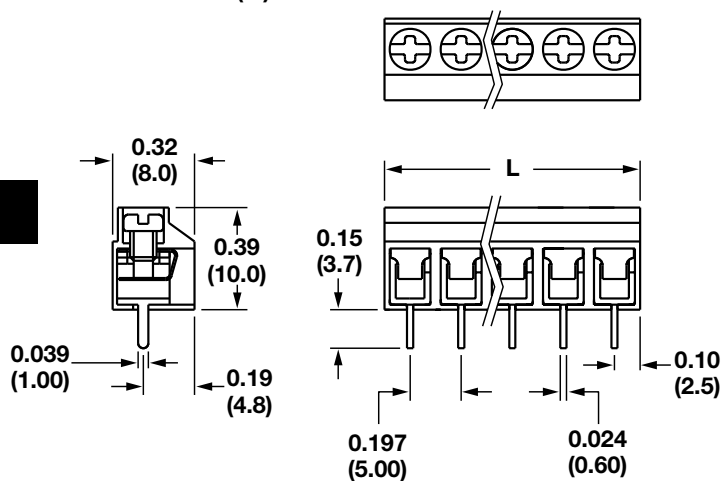

Part Numbering System

Series

of Poles



Terminal Blocks:
Single Row

EuroMag Series
Spring & Screw

Edge Connectors,
One-Sided Boards

Compliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM367502](#) [EM367503](#) [EM367504](#) [EM367505](#) [EM367506](#) [EM367507](#) [EM367508](#) [EM367509](#) [EM367510](#)
[EM367512](#) [EM367514](#) [EM367525](#) [EM367527](#) [EM367516](#) [EM367515](#) [EM367517](#) [EM367519](#) [EM367526](#)
[EM367520](#) [EM367521](#) [EM367518](#) [EM367522](#) [EM367523](#) [EM367524](#) [EM367511](#) [EM367513](#)