

Rail mount terminal blocks

NDN Series

Specifications


Description: High-density, snap-on 35mm DIN rail compatible rail mount terminal blocks.

Construction: Unique, impact resistant, one-piece thermoplastic moldings. Heat treated stainless steel collars (to secure wires). Tin-plated copper alloy terminals. Zinc-plated steel screws.

Circuits Per Foot: Up to 48 circuits per foot.

Agency Information: CE, UL E62622; CSA LR15364.

Flammability Rating: UL 94V2

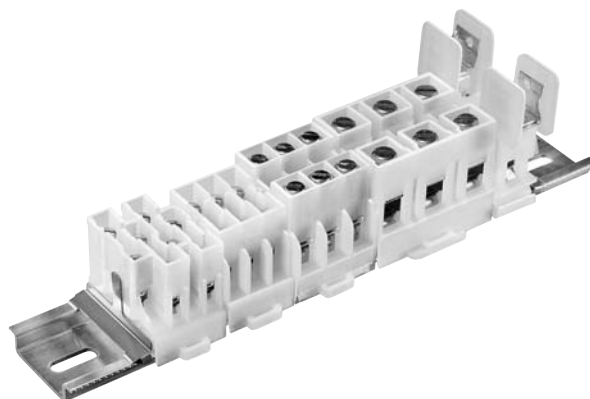

NDNV4-__ __ (color)

Specifications

Description: Rail mount terminal block.

Center Spacing: 0.250" (6.35).

Circuit Jumper: JN4, 4 circuits.

Screw Size: #6-32.

Poles: 4

Circuits Per Foot: 48

Wire Range: AWG #10-22 CU.

Ratings:

Volts: — 600V

Amps: — 0-30A

Agency Information: CE, UL E62622; CSA LR15364.

Flammability Rating: UL 94V2.

Marking Tape: MTC6.

Torque Rating: 18 in-lb max.

Mounting Options: 35mm DIN rail, C-rail.

Catalog Numbers

Catalog

Numbers	Colors
NDNV4-WH	WH - White (Standard)
NDNV4-BK	BK - Black



NDN3-__ __ (color)

Specifications

Description: Rail mount terminal block.

Center Spacing: 0.300" (7.62).

Circuit Jumper: JNDN3, 2 circuits.

Screw Size: #6-32.

Poles: 3

Circuits Per Foot: 38

Wire Range: AWG #10-22 CU.

Ratings:

Volts: — 600V

Amps: — 0-30A (field wiring)

— 0-30A (factory wiring)

Agency Information: CE, UL E62622; CSA LR15364.

Flammability Rating: UL 94V2

Marking Tape: MT12-½.

Torque Rating: 18 in-lb max.

Mounting Options: 35mm DIN rail, C-rail.

Catalog Numbers

Catalog

Numbers	Colors
NDN3-WH	WH - White (Standard)
NDN3-BK	BK - Black



NDN63-__ __ (color)

Specifications

Description: Rail mount terminal block.

Center Spacing: 0.375" (9.52).

Circuit Jumper: JN3, 2 circuits.

Screw Size: #10-32.

Poles: 3

Circuits Per Foot: 30

Wire Range: AWG #6-18 CU.

Ratings:

Volts: — 600V

Amps: — 0-65A

Agency Information: CE, UL E62622; CSA LR15364.

Flammability Rating: UL 94V2

Marking Tape: MT12-½.

Torque Rating: 35 in-lb max.

Mounting Options: 35mm DIN rail, C-rail.

Catalog Numbers

Catalog

Numbers	Colors
NDN63-WH	WH - White (Standard)
NDN63-BK	BK - Black

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[NDNV4-BK](#) [NDN3-BK](#)