

Series TB300 & TB345

Double Row Terminal Blocks

SPECIFICATIONS

Rating: TB300 – 30A, 600V*

TB345 – 45A, 600V*

Center Spacing: .562" or 9/16" (14.28 mm)

Wire Size: #10 - 22 AWG CU

Screw Size: TB300 – #8-32 philslot screws

TB345 – #10-32 philslot screws

Torque Rating: #8 screws - 16 in-lb.;

#10 screws - 20 in-lb.

Distance Between Barriers: .41" (10.5 mm)

Mounting: TB300 – #8 screws; TB345 – #10 screws

Material: Molded base: Black, UL rated 94VO thermoplastic

Terminal plating: Tin over brass; Screws: Zinc plated steel

Operating Temperature: 130°C (260°F) max., -40°C (-40°F) min.

Breakdown Voltage: 7500V rms

Approvals: UL E62622; CSA LR15364; IEC Compliance;

CE Certified


* Max. rating shown; some options may be rated lower - consult factory.



Poles	A	B	Poles	A	B	Poles	A	B
02	2.13	1.69	10	6.62	6.19	18	11.12	10.68
03	2.69	2.25	11	7.18	6.75	19	11.68	11.25
04	3.25	2.81	12	7.75	7.31	20	12.24	11.81
05	3.81	3.37	13	8.31	7.87	21	12.80	12.37
06	4.37	3.94	14	8.87	8.44	22	13.37	12.93
07	4.94	4.50	15	9.43	9.00	23	13.93	13.50
08	5.50	5.06	16	9.99	9.56	24	14.49	14.06
09	6.06	5.62	17	10.56	10.12			

* Dimensions in inches. To convert to millimeters, multiply by 25.4.

TB300 & TB345

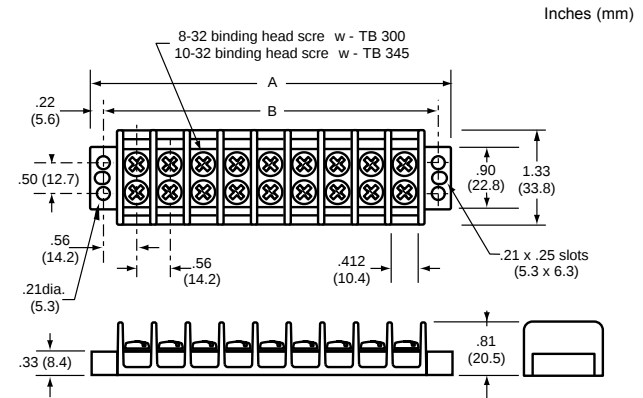

Part Numbering System

Series

TB **300** **08**
 300 - 8/32 screw
 345 - 10/32 screw

Poles

02 **24**
 02 to 24

Screw Options

Blank - std. screws
00 - screws shipped bulk
B - brass philslot, nickel plated
BS - brass Sems philslot, zinc plated (TB300 only)
SP - steel Sems philslot, zinc plated
ST - stainless steel, philslot

Marking

L1 to **L6** - std. marking
 Marker strips (pg 33)
 Covers (pg 32)

Hardware Options

QC1 to **QC20** - quick connects (TB300 only)

Screw Options



B
Brass Philslot
Nickel Plated



BS
Brass SEMS
Philslot Nickel Plated



SP
Steel SEMS
Philslot Zinc Plated



ST
Stainless Steel
Philslot

Hardware Options


Quick Connects – Assembled TB300 only. Terminals .250" x .031". Max. current rating 20 Amps. For other orientations, contact factory.




QC1



 
QC2




QC3

 


QC4

 

QC5

 

QC6

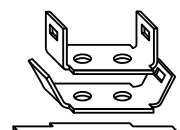

QC7




QC8




QC9



 
QC10



QC11

 

QC12

 


QC13




QC14



 
QC15




QC16

 


QC17

 

QC18

 

QC19

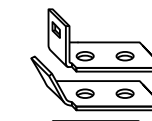

QC20


Quick Connects – Bulk *TB300 only. Min. order per part no. – 100 pieces.



QC201
Flat – none



 QC202
QC 45° – none



QC203
QC 90° – none



QC204
Flat – Flat



QC205
Flat – QC 45°



QC206
Flat – QC 90°



QC207
QC 45° – QC 45°



QC208
QC 45° – QC 90°




QC209
QC 90° – QC 90°


Jumpers – Bulk Min. order per part no. – 100 pieces. Contact factory for jumper assembly.



J301
Flat slip-on
(TB300 only)

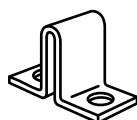

OJ6
Closed over barrier

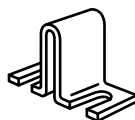

OJ11
Slip-on over barrier

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[TB300-12L3QC4](#)