

Series 14004

Dead Front Terminal Blocks


SPECIFICATIONS

Rating: 90A, 600V
Poles: 2 to 12 poles
Wire Range: #4-14 AWG CU / #4-8 AWG AL
Torque Rating: 4-6AWG 35 in-lb., 8AWG 25 in-lb., 10-14AWG 20 in-lb.
Operating Temperature: 75°C
Marking: Marking strip optional, consult factory.
Agency Information: UL/CSA; CE Certified



Part Number	A	B
14004-2	1.81	1.43
14004-3	2.31	1.93
14004-4	2.81	2.43
14004-5	3.31	2.93
14004-6	3.81	3.43
14004-7	4.31	3.93
14004-8	4.81	4.43
14004-9	5.31	4.93
14004-10	5.81	5.43
14004-11	6.31	5.93
14004-12	6.81	6.43

* Dimensions in inches. To convert to millimeters, multiply by 25.4.

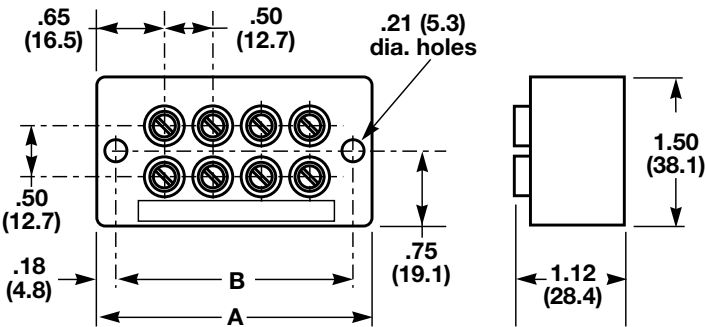

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[14004-11](#)