

Series 11675

Quick-Connect Power Distribution Blocks

SPECIFICATIONS

Rating: 40A, 250V

Poles: 2 to 6 poles with (3) .250" quick-connect terminals per pole

Wire Range: #8-14 AWG CU



Torque Rating: 18 in.-lb.

Operating Temperature: 150°C

Design: Screw connections for field wiring. Quick connects reduce cost of internal wiring.

Breakdown Voltage:

Agency Information: UL/CSA; CE Certified

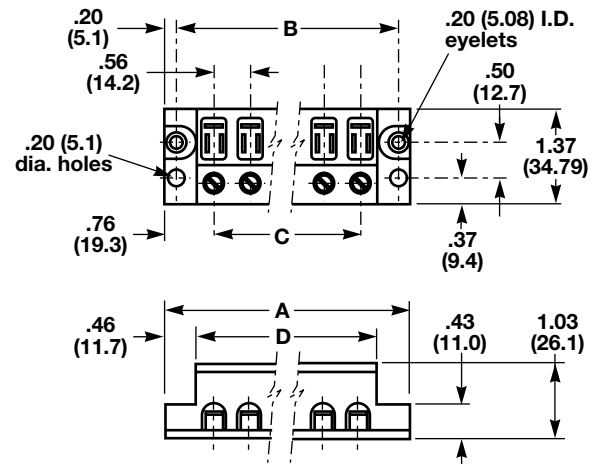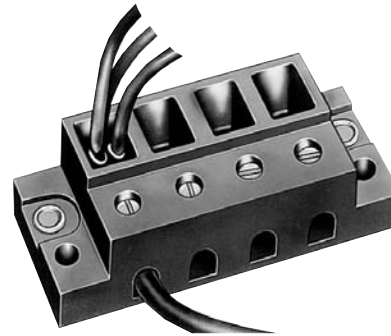

* Dimensions in inches. To convert to millimeters, multiply by 25.4.

Series 11725

Quick-Connect Power Distribution Blocks

SPECIFICATIONS

Rating: 70A, 600V; UL/CSA

Poles: 2, 3 or 4 poles with (4) .250" quick-connect terminals per pole


Wire Range: #2-14 AWG CU / #2-8 AWG AL

Torque Rating: 45 in.-lb.

Operating Temperature: 150°C

Design: Screw connections for field wiring. Quick connects reduce cost of internal wiring.

Agency Information: UL/CSA E62622; CE Certified

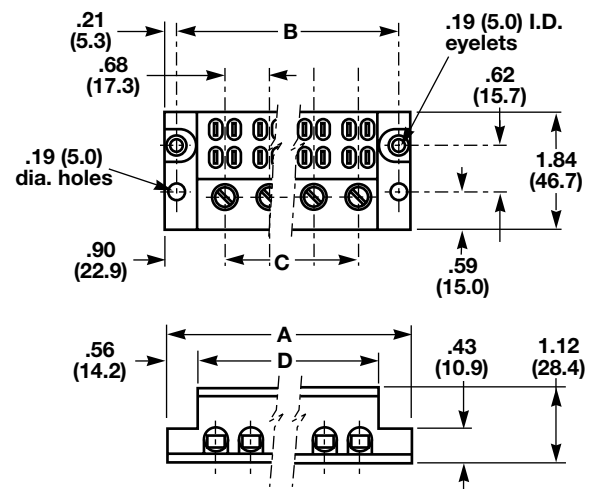

* Dimensions in inches. To convert to millimeters, multiply by 25.4.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[11725-3](#) [11725-2](#) [11725-4](#) [11675-4](#) [11675-6](#)