


## Fast-Acting 1/4" x 7/8" Glass Tube Fuses AGW Series



Dimensions - in

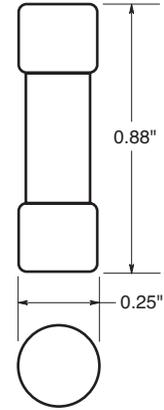

### Description

- Fast-acting
- 1/4" x 7/8" (6.3 x 22.2mm) physical size
- Glass tube, nickel-plated brass endcap construction
- Mounts in in-line holders HHB (data sheet # 2103), HHK, HRK (data sheet # 2111) or PCB fuseclips for 1/4" fuses (1A1119, 1A1120, 1A1907, 1A3398, 1A4533 and 1A4534 - data sheet # 2131)

### Ordering


#### Specify product code

- Insert packaging code prefix before part number, E.g., BK/AGW-1

Part Number (Amps)	Voltage Rating Vac	Specifications		Typical DC Cold Resistance (Ω)*	
		Interrupting Rating (amps) at Rated Voltage AC	Lower	Upper	
AGW-1	32	1000	0.100	0.135	
AGW-1-1/2	32	1000	0.060	0.080	
AGW-2	32	1000	0.042	0.056	
AGW-2-1/2	32	1000	0.029	0.040	
AGW-3	32	1000	0.027	0.036	
AGW-4	32	1000	0.018	0.024	
AGW-5	32	1000	0.013	0.018	
AGW-6	32	1000	0.010	0.014	
AGW-7-1/2	32	1000	0.009	0.012	
AGW-10	32	1000	0.006	0.008	
AGW-15	32	1000	0.003	0.005	
AGW-20	32	1000	0.002	0.003	
AGW-25	32	1000	0.002	0.003	
AGW-30	32	1000	0.001	0.002	

\* DC Cold Resistance (Measured at <10% of rated current)

### Time-Current Curves

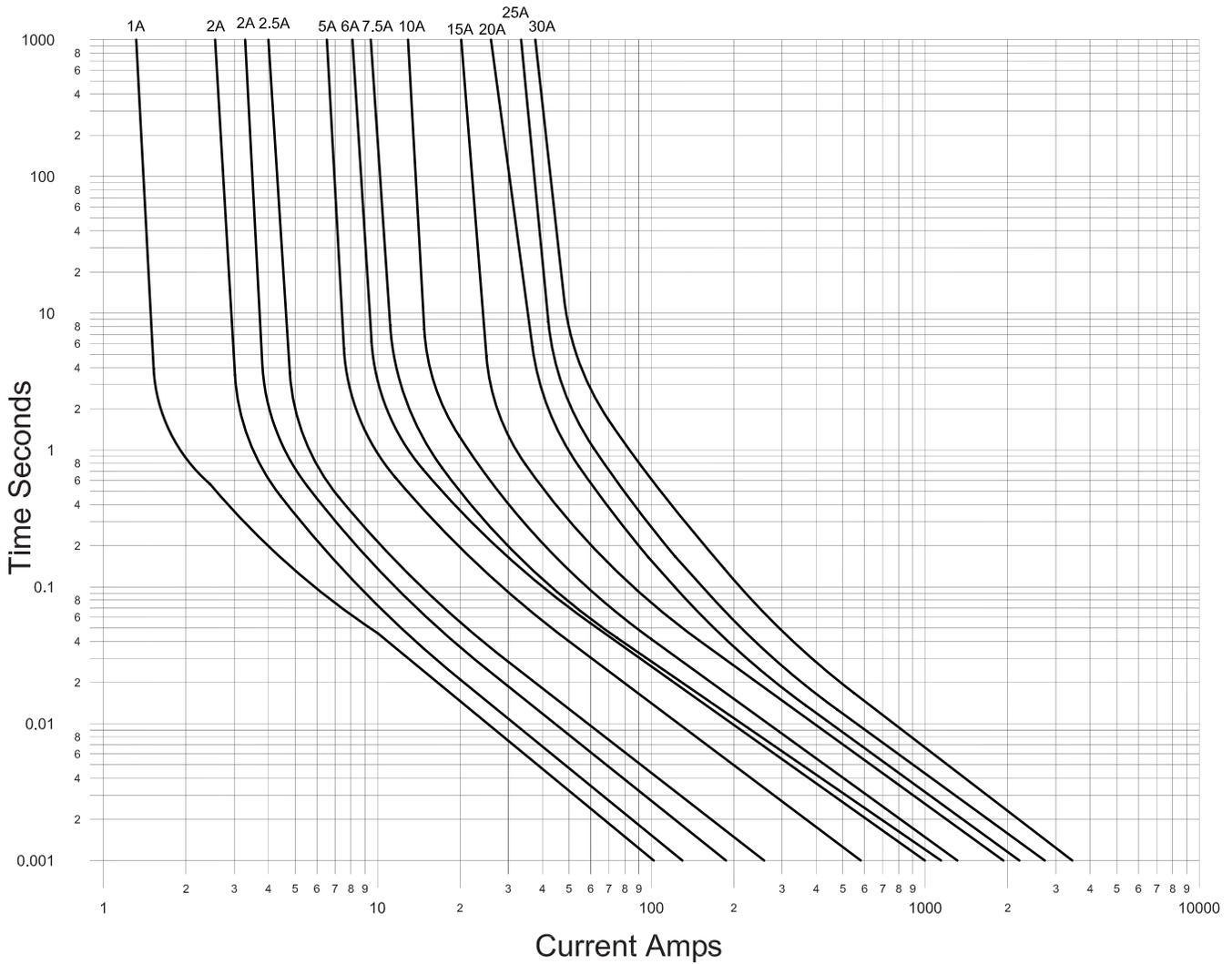

Packaging Code	
Packaging Code Prefix	Description
BK	100 fuses packed into a cardboard carton

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Eaton:

[AGW-10](#) [AGW-15](#) [AGW-20](#) [AGW-25](#) [AGW-3](#) [AGW-30](#) [AGW-4](#) [AGW-5](#) [AGW-6](#) [BK/AGW-1](#) [BK/AGW-10](#)  
[BK/AGW-15](#) [BK/AGW-2](#) [BK/AGW-20](#) [BK/AGW-2-1/2](#) [BK/AGW-3](#) [BK/AGW-30](#) [BK/AGW-4](#) [BK/AGW-5](#) [BK/AGW-6](#)  
[BK/AGW-7-1/2](#) [AGW-1-1/2](#) [AGW-2-1/2](#) [AGW-7-1/2](#)