


Multi-Device Charging Station, 16 USB Ports, iPad and Android Tablets, Wall-Mount Option Black

MODEL NUMBER: **CS16USB**

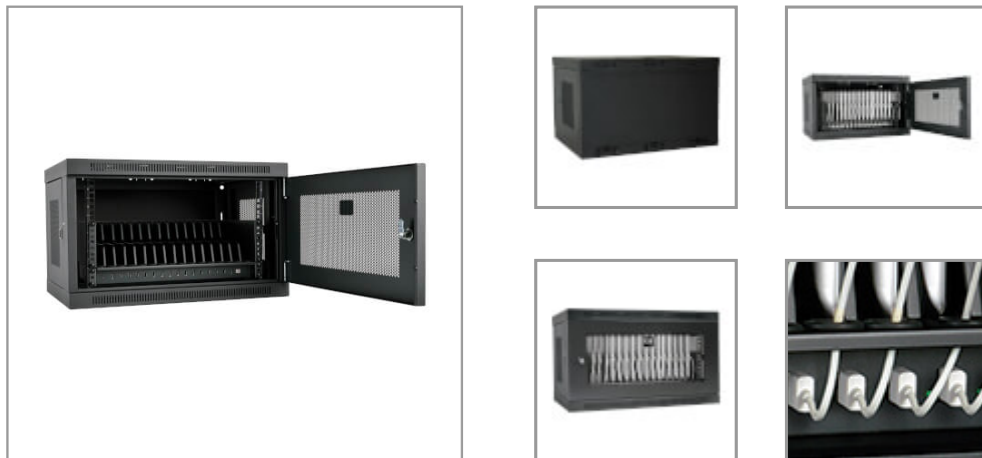

Locking steel cabinet provides 2.4A USB charging, syncing, secure storage and cord management for up to 16 tablets and other USB devices. Recommended for education, office, commercial, retail, industrial and healthcare environments.

Features

Fast Charging

- 16 USB ports provide fastest charging supported by each device, up to 2.4A per port
- Recommended for iPad®, Android™, Surface™ and Kindle™ tablets
- Also charges mobile phones and other USB devices
- Detachable 10-ft. (3.05 m) AC input cord with NEMA 5-15P plug

Convenient Syncing

- USB sync uplink port connects to host computer for wired syncing
- Compatible with wireless syncing
- Supports simultaneous syncing and charging (up to 1.5A per port during wired syncing)

Comprehensive Protection

- Sturdy steel construction and powder-coated finish promote long-term durability
- Doors lock with included keys to help prevent device theft, damage or tampering
- Flow-through ventilation helps prevent devices from overheating
- Coated shelf shields devices from scratches and scuffs

Flexible Configuration

- Ships fully assembled
- Supports mounting to wall, desk, table, counter or floor
- Door opens 180 degrees for improved device and service access
- Removable dividers accommodate thicker devices
- Firmware upgrade port for future updates

Highlights

- Fast 2.4A USB charging, syncing and storage for 16 devices
- Locking steel cabinet with flow-through ventilation
- Adjustable device dividers and integrated cord management
- Ships fully assembled and mounts to wall, desk, table or floor
- Detachable 10-ft. (3.05 m) power cord

Package Includes

- CS16USB 16-Device USB Charging Station Cabinet, Black
- Detachable 10-ft. (3.05 m) AC input cord w/NEMA 5-15P plug
- (2) Keys
- Owner's manual



Powering Business Worldwide

TRIPP LITE
SERIES

Specifications

| OVERVIEW | |
|------------------------------------|--------------------------|
| UPC Code | 037332185419 |
| Product Type | Multi-Device Charger |
| Charging Form Factor | Stationary Cabinet |
| Charger Functions | Charge; Secure; Sync |
| Device Compatibility | Tablet; Phone |
| Device Slots | 16 |
| INPUT | |
| Nominal Input Voltage(s) Supported | 120V AC; 230V AC |
| Voltage Compatibility (VAC) | 110-240 |
| Input Frequency | 50 / 60 Hz (auto-select) |
| Input Plug Type | NEMA 5-15P |
| Input Cord Length (ft.) | 10 |
| Input Cord Length (m) | 3.05 |
| POWER | |
| Power Consumption (Watts) | 56 |
| CHARGING | |
| Number of Charging Ports | 16 |
| Total Charging Amps | 40A |
| Charging Method | USB |
| Charging Port Type | USB A (FEMALE) |
| Charging Ports Details | Pass through |
| Charging Ports / Amps | (16) 2.4A |
| Overcharge Protection | Yes |
| Charging Amps per Port | 2.4A |
| PHYSICAL | |
| Color | Black |
| Material of Construction | Steel |
| Charging Station Form Factor | Stationary Cabinet |
| Shipping Dimensions (hwd / in.) | 18.20 x 21.20 x 26.80 |



Powering Business Worldwide

TRIPP LITE
SERIES

| | |
|--------------------------------|--------------------------|
| Shipping Dimensions (hwd / cm) | 46.23 x 53.85 x 68.07 |
| Shipping Weight (lbs.) | 62.00 |
| Shipping Weight (kg) | 28.12 |
| Slot Dimensions (hwd / in.) | 8,1 x 0,8 x 13,9 |
| Slot Dimensions (hwd / mm) | 206 x 20,1 x 353,8 |
| Unit Dimensions (hwd / in.) | 14.570 x 23.620 x 17.720 |
| Unit Dimensions (hwd / cm) | 37,01 x 59,99 x 45,01 |
| Unit Weight (lbs.) | 55.14 |
| Unit Weight (kg) | 25.01 |
| Number of Shelves | 1 |

FEATURES & SPECIFICATIONS

| | |
|-------------------------------|-----|
| Antimicrobial | No |
| Built-In Circuit Breaker | Yes |
| Cord Management | Yes |
| Overcurrent Protection | Yes |
| EMI/RFI Line Noise Protection | No |
| Flow-Through Ventilation | Yes |
| IP68 Rated | No |
| IP20 Rated | No |
| UV Sterilization | No |
| Locking | Yes |
| Lock Type | Key |

STANDARDS & COMPLIANCE

| | |
|------------------------|--|
| Product Certifications | NOM (Mexico); UL 60950-1 |
| Product Compliance | RoHS; CE (Europe); EIA/ECA-310-E; REACH; FCC Part 15 Class B (USA) |

WARRANTY & SUPPORT

| | |
|-------------------------------------|-------------------------|
| Product Warranty Period (Worldwide) | 2-year limited warranty |
|-------------------------------------|-------------------------|

CATEGORY PAGE FILTERS (Y/N ONLY)

| | |
|---------------------|----|
| External Receptacle | No |
|---------------------|----|



Powering Business Worldwide

TRIPP LITE
SERIES

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[CS16USB](#)