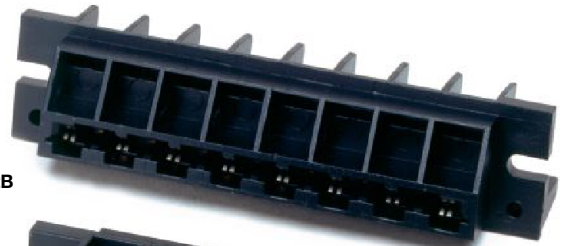


Series 1384XEdge Connectors –
1 Sided Boards/Vertical Mount**SPECIFICATIONS****Rating:** 10A, 250V**Center Spacing:** 0.375" or 9.52mm**Wire Range:** #14-22 AWG Cu; entry to PC board at 90° angle.**Number of Poles:** 4- to 16-poles**PC Board:** Edge contact accepts standard 1/6" (0.0625) PCB.**Contacts:** Cantilever design 0.02" thick phosphorus bronze with mating surface tin-plated (0.0002) over copper (0.00005).**Terminals:** Pressure plate terminals.**Material:** Black, UL Rated 94V0 Thermoplastic (125°C)**Operating Temperature:** -55°C to 105°C (212°F)**Agency Information:** File E62622; CSA File 47235

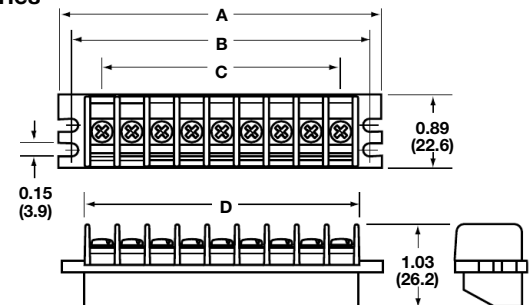
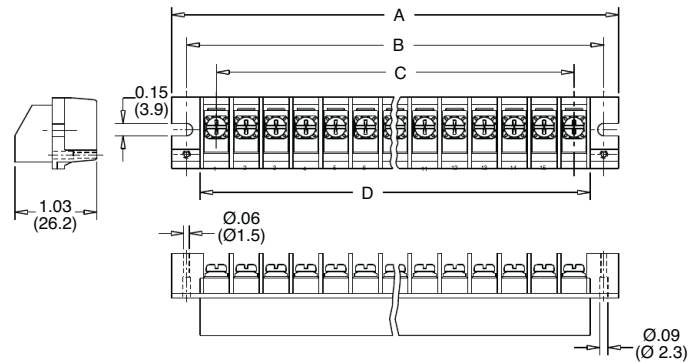
13848-08G02B



13847-08T02B

Poles	A	B	C	D
04	2.25	1.87	1.12	1.53
05	2.62	2.25	1.50	1.90
06	3.00	2.62	1.87	2.28
08	3.75	3.37	2.62	3.03
10	4.50	4.12	3.37	3.78
12	5.25	4.87	4.12	4.53
14	6.00	5.62	4.87	5.28
16	6.75	6.37	5.62	6.03
18	7.50	7.12	6.37	6.40

* Dimensions in inches. To convert to millimeters, multiply by 25.4.
Optional polarizing key (Part No. C5971) consult with factory.

Dimensions - in (mm)**13847 Series****13848 Series****Part Numbering System**

Series	Block Style	Poles	Terminal Plating	Screw Style	Block Color	Special Options
1384				02	B	
	7 - Flat mtg. ears w/ 2 slots 8 - Mtg. ears w/2 standoffs with hole for mounting strip	04 to 18	T - Tin over copper G - Gold*	02 - #6-32 pan head. w/ SEMS wire clamp	B - Black	M - Marking strip

* Consult Factory

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[13848-18G02B](#) [13847-10G02B](#) [13847-10T02B](#) [13847-14G02B](#) [13847-16G02B](#) [13847-16T02B](#) [13848-05G02B](#)
[13848-08G02B](#) [13848-08G02B-M](#) [13848-14G02B](#) [13848-18T02B](#)