

EM2211 Series**EuroMag Terminal Blocks**

Header with Flanges (Mates with EM2423, EM2443 Series); 3.81 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.15" (3.81mm)

Consult factory for 0.30" (7.62mm)

Housing Material: UL rated 94V0 Thermoplastic

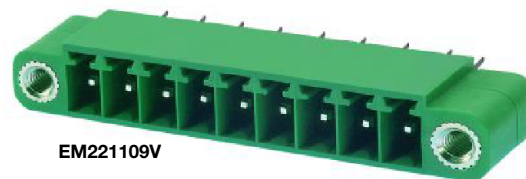
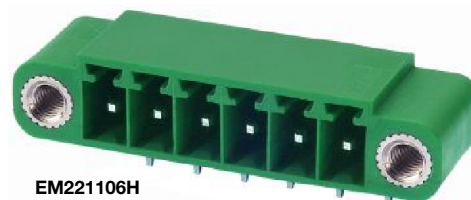
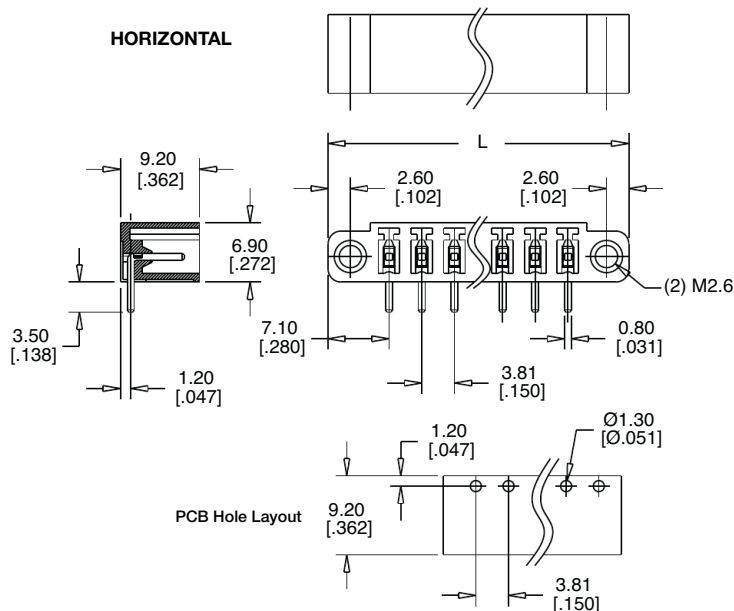
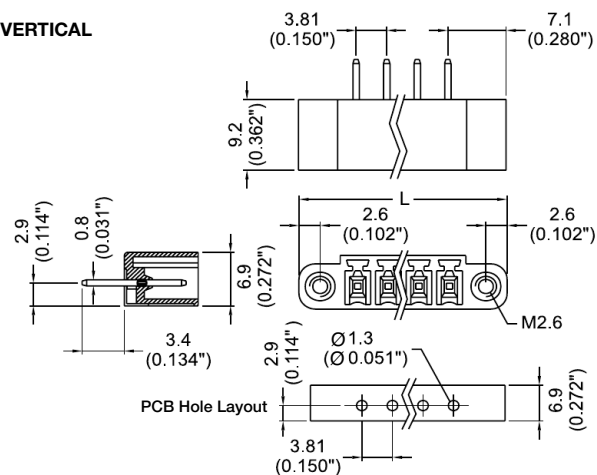
Contact Material: Brass Tin-Plated

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Recommended PCB Hole Diameters: 0.055" (1.40mm)

Construction: Mold to Length

Agency Information: cULus File E62622; CE Certified

**Dimensions - mm (in)****HORIZONTAL****VERTICAL****Poles L (mm)**

Poles	L (mm)
2	18.02
3	21.83
4	25.64
5	29.45
6	33.26
7	37.07
8	40.88
9	44.69
10	48.50
11	52.31
12	56.12
14	63.74

To convert to inches, divide by 25.4

Part Numbering System

Series

EM2211

of Poles

02 to 14

Orientation

H - horizontal
V - vertical

Mating Plugs: EM2423 pg. 82
EM2443 pg. 83

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM221102V](#) [EM221103V](#) [EM221104H](#) [EM221106H](#) [EM221112V](#) [EM221103H](#) [EM221108V](#) [EM221111V](#)
[EM221114V](#) [EM221112H](#) [EM221107V](#) [EM221108H](#) [EM221105V](#) [EM221106V](#) [EM221109H](#) [EM221107H](#)
[EM221110V](#) [EM221111H](#) [EM221110H](#) [EM221102H](#) [EM221114H](#) [EM221104V](#) [EM221109V](#) [EM221105H](#)