

Series EM2215

Header with Flanges; (Mates with EM2115, EM3115 Series); 5.00 Centers

SPECIFICATIONS:

Rating: 16A, 300V

Center Spacing: 0.197" (5.00mm)

Housing Material: UL rated 94V0 Thermoplastic

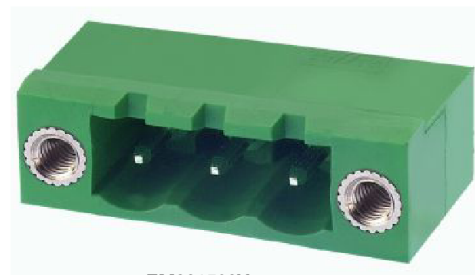
Contact Material: Tin-Plated Brass

Operating Temperature: 105°C (221°F) max., -55°C (-67°F) min.

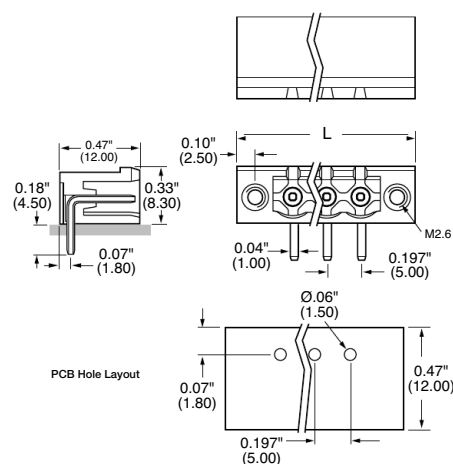
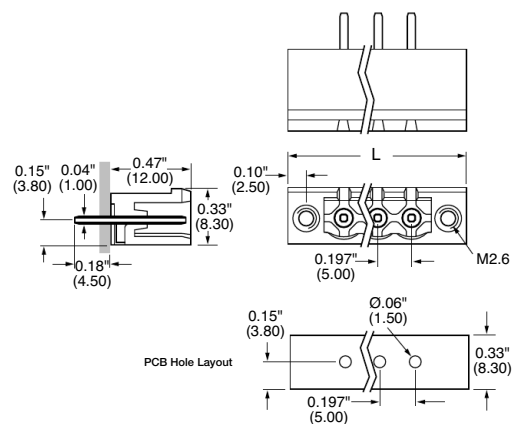
Construction: Mold-to-Length

Agency Information: cULus File E62622; CE Certified

Poles	L (mm)	L (Inch)	Poles	L (mm)	L (Inch)
2	20.0	0.787	13	75.0	2.952
3	25.0	0.984	14	80.0	3.149
4	30.0	1.181	15	85.0	3.346
5	35.0	1.378	16	90.0	3.543
6	40.0	1.575	17	95.0	3.740
7	45.0	1.772	18	100.0	3.937
8	50.0	1.969	19	105.0	4.133
9	55.0	2.165	20	110.0	4.330
10	60.0	2.362	21	115.0	4.527
11	65.0	2.559	22	120.0	4.724
12	70.0	2.756			



EM221503V

Dimensions - in (mm)**HORIZONTAL****VERTICAL****Part Numbering System**

Inches (Millimeters)

Series

EM2215

of Poles

02 to 22

Orientation

H - Horizontal
V - Vertical

Mating Plugs: EM2115 pg. 93
EM3115 pg. 94

Terminal Blocks:
Single RowEuroMag Series
Plug & HeaderEdge Connectors,
One-Sided BoardsCompliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

<u>EM221504H</u>	<u>EM221504V</u>	<u>EM221506H</u>	<u>EM221506V</u>	<u>EM221508V</u>	<u>EM221502V</u>	<u>EM221503H</u>	<u>EM221505H</u>
<u>EM221507V</u>	<u>EM221511V</u>	<u>EM221516V</u>	<u>EM221520V</u>	<u>EM221507H</u>	<u>EM221510H</u>	<u>EM221513H</u>	<u>EM221515V</u>
<u>EM221517V</u>	<u>EM221517H</u>	<u>EM221519V</u>	<u>EM221505V</u>	<u>EM221509H</u>	<u>EM221521H</u>	<u>EM221522H</u>	<u>EM221516H</u>
<u>EM221510V</u>	<u>EM221520H</u>	<u>EM221511H</u>	<u>EM221512H</u>	<u>EM221513V</u>	<u>EM221512V</u>	<u>EM221521V</u>	<u>EM221522V</u>
<u>EM221515H</u>	<u>EM221508H</u>	<u>EM221518H</u>	<u>EM221514H</u>	<u>EM221519H</u>	<u>EM221503V</u>	<u>EM221509V</u>	<u>EM221502H</u>
<u>EM221514V</u>	<u>EM221518V</u>						