

EM2416 Series
EuroMag Terminal Blocks
Pluggable Block with Flanges (Mates with
EM2426 Series); 7.62 Centers

SPECIFICATIONS
Rating: 16A, 300V
Center Spacing: 0.30" (7.62mm)
Wire Range: #12-24 AWG
Housing Material: UL rated 94V0 Thermoplastic
Contact Material: Tin-Plated Brass
Cage Material: Brass, Nickel-Plated
Screw Size: M2.6 Zinc-Plated Steel
Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.
Torque Rating: 7.0 lb-in.
Construction: Mold-to-Length
Agency Information: File E62622; CE Certified




EM241602

Poles	L (mm)
2	24.90
3	32.50
4	40.10
5	47.80
6	55.40
7	63.00
8	70.60
9	78.20
10	89.90
11	93.50
12	101.10

To convert to inches, divide by 25.4

Dimensions - mm

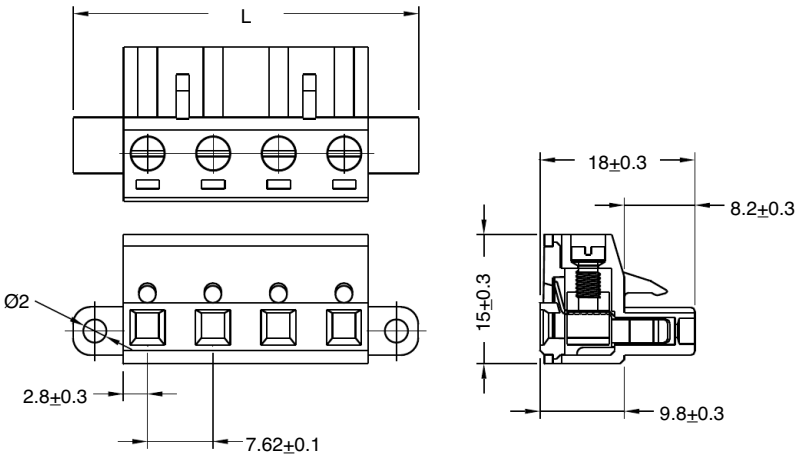

Part Numbering System

Series # of Poles

EM2416

02 to 12

Mating Header: EM2426 pg. 102

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM241608](#) [EM241602](#) [EM241606](#) [EM241610](#) [EM241605](#) [EM241609](#) [EM241611](#) [EM241603](#) [EM241612](#)
[EM241604](#) [EM241607](#)