

EM2565 Series**EuroMag Terminal Blocks**

Pluggable Block (Mates with EM2575 Series); 5.08 Centers

SPECIFICATIONS

Rating: 16A, 300V

Center Spacing: 0.20" (5.08mm)

Consult factory for 0.40" (10.16mm)

Wire Range: #12-24 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass Tin-Plated

Screw Size: M3.0 Zinc-Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

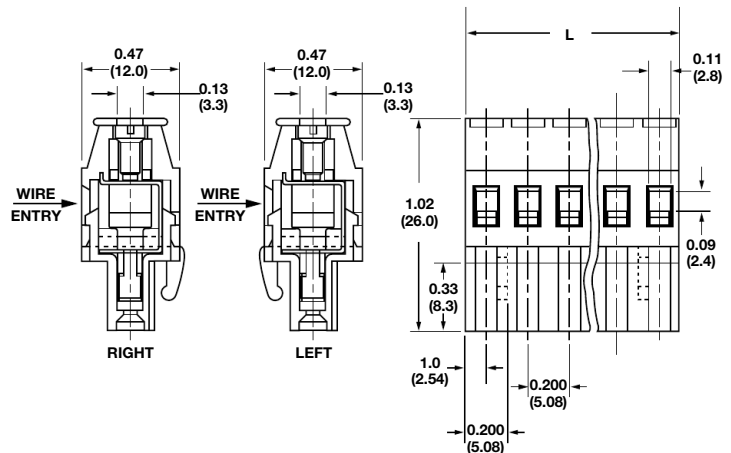
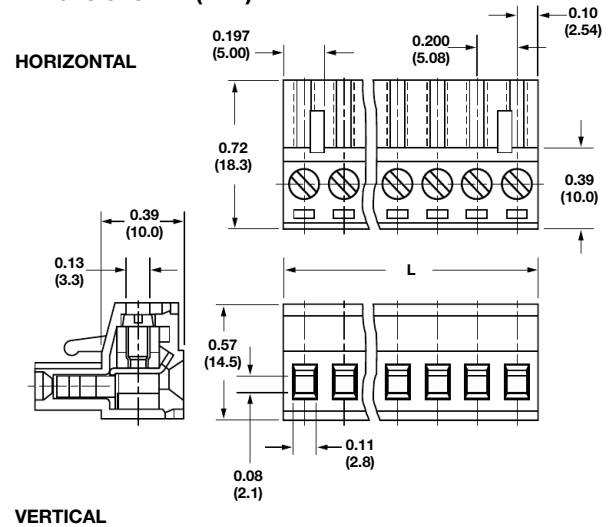
Torque Rating: 7 lb-in.

Construction: Mold-to-Length

Agency Information: e-us File E62622; CE Certified



EM256503H

Dimensions - in (mm)

To convert to inches, divide by 25.4

Part Numbering System

Series	# of Positions	Orientation	Wire Entry (Vertical Orientation Only)	Mating Header: EM2575 pg. 92
EM2565				
	02 to 24	H - horizontal V - vertical	L - left R - right	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM256516H](#) [EM256516VR](#) [EM256524VL](#) [EM256507VL](#) [EM256517H](#) [EM256520VR](#) [EM256517VL](#) [EM256515VL](#)
[EM256513VL](#) [EM256523VR](#) [EM256519VL](#) [EM256522VR](#) [EM256509VR](#) [EM256511VR](#) [EM256518VL](#) [EM256517VR](#)
[EM256521VL](#) [EM256522H](#) [EM256522VL](#) [EM256523H](#) [EM256524H](#) [EM256520VL](#) [EM256519H](#) [EM256524VR](#)
[EM256521H](#) [EM256518VR](#) [EM256519VR](#) [EM256520H](#) [EM256514VL](#) [EM256516VL](#) [EM256515VR](#) [EM256521VR](#)
[EM256523VL](#) [EM256518H](#) [EM256504S2463](#)