

EM2778 Series

EuroMag Terminal Blocks

Screwless, Modular, 5.08 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.20" (5.08mm)

Wire Size: #16-26AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Tin-Plated Brass

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Recommended PCB Hole Diameters: 0.051" (1.30mm)


Construction: Modular design features dovetails for interlocking to achieve longer lengths

Agency Information:  File E62622; CE Certified



EM277805

Dimensions - mm (in)

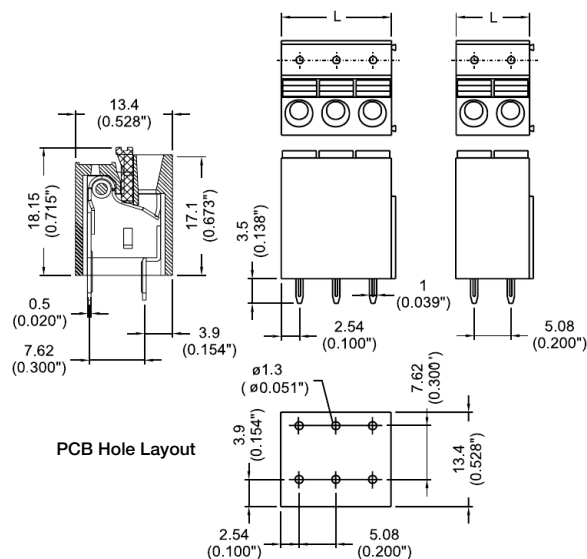

Poles	L (mm)	Poles	L (mm)
2	10.16	14	71.12
3	15.24	15	76.20
4	20.32	16	81.28
5	25.40	17	86.36
6	30.48	18	91.44
7	35.56	19	96.52
8	40.64	20	101.16
9	45.72	21	106.68
10	50.80	22	111.76
11	55.88	23	116.84
12	60.96	24	121.92
13	66.04		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM2778

02 24

02 to 24

Terminal Blocks:
Single Row

EuroMag Series
Screwless

Edge Connectors,
One-Sided Boards

Compliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM277821](#) [EM277822](#) [EM277802](#) [EM277813](#) [EM277823](#) [EM277803](#) [EM277806](#) [EM277818](#) [EM277820](#)
[EM277804](#) [EM277811](#) [EM277816](#) [EM277819](#) [EM277809](#) [EM277805](#) [EM277824](#) [EM277817](#) [EM277812](#)
[EM277808](#) [EM277814](#) [EM277807](#) [EM277810](#) [EM277815](#)