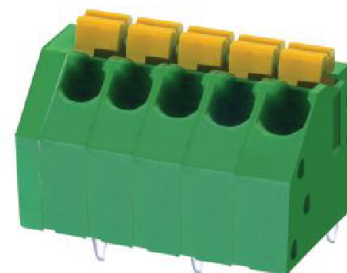
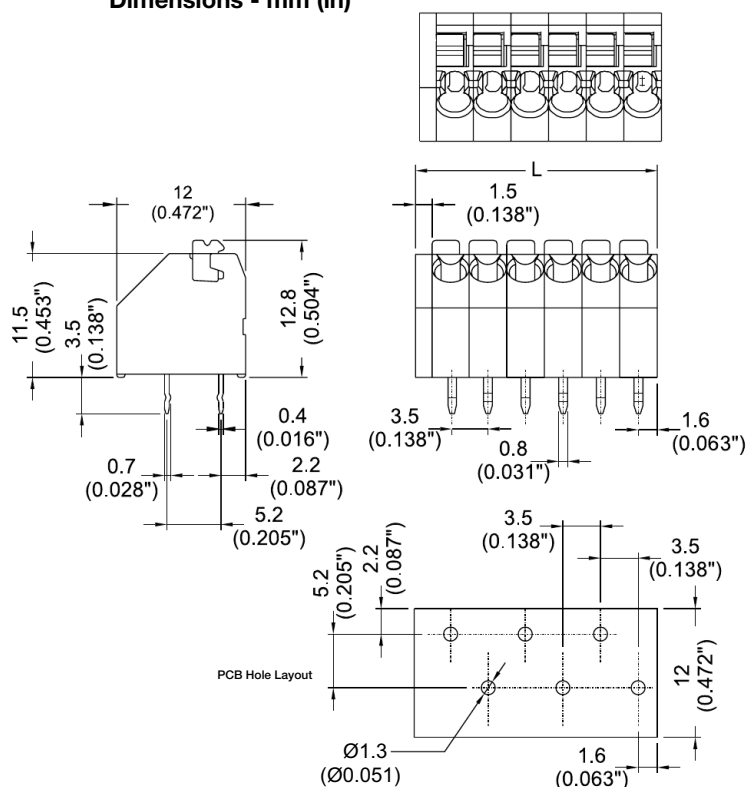


EM2783 Series**EuroMag Terminal Blocks**

45° Entry; Screwless; 3.50 Centers

SPECIFICATIONS**Rating:** 6A, 300V**Center Spacing:** 0.136" (3.50mm)**Wire Range:** #14-20 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Tin Plated Phos Bronze**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Recommended PCB Hole Diameters:** 0.051" (1.30mm)**Construction:** Mold-to-Length**Agency Information:**  File E62622; CE Certified**EM278305****Dimensions - mm (in)**

Poles	L (mm)
2	8.5
4	15.5
6	22.5
8	29.5
10	36.5
12	43.5
14	50.5
16	57.5
18	64.5
20	71.5
22	78.5
24	92.5

To convert to inches, divide by 25.4

Part Numbering System**Series****# of Poles****EM2783****02****02 to 24**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM278306](#) [EM278312](#) [EM278308](#) [EM278320](#) [EM278324](#) [EM278302](#) [EM278310](#) [EM278304](#) [EM278316](#)
[EM278318](#) [EM278322](#) [EM278314](#)